


## Cable Labeling

### Self-Laminating Self-Adhesive Labels



- White print-on area is highly legible
- Clear overlaminate protects legend
- Some sizes available with TIA recommended colors on the print-on area
- Adhesive designed to insure long term bonding
- Some parts available in self-extinguishing TEDLAR▲ material for high performance applications or outdoor use

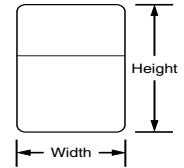

Part Number	Material	Total Area Width x Height In. (mm)	Print-On Area Width x Height In. (mm)	Nominal Cable Outside Diameter In. (mm)	Typical UTP	Typical Fiber	Std. Pkg. Qty.
<b>For Desktop Laser and Ink Jet Printers</b>							
LJSL4-Y3-2.5*	GMV3	1.00 x 1.00 (25.4 x 25.4)	1.00 x 0.34 (25.4 x 8.6)	0.11-0.21 (2.8-5.3)	4 Pair	2-4 Strand	2500
LJSL5-Y3-2.5*	Self-Laminating Polyester (Indoor/Outdoor)	1.00 x 1.33 (25.4 x 33.8)	1.00 x 0.47 (25.4 x 11.9)	0.15-0.27 (3.8-6.8)	4 Pair	2-12 Strand	2500
LJSL7-Y3-1		2.00 x 1.50 (50.8 x 38.1)	2.00 x 0.50 (50.8 x 12.7)	0.16-0.32 (4.1-8.1)	4 Pair	2-18 Strand	1000
LJSL6-Y3-1		1.00 x 3.17 (25.4 x 80.5)	1.00 x 0.97 (25.4 x 24.6)	0.31-0.70 (7.9-17.8)	25 Pair	24-132 Strand	1000
LJSL8-Y3-1		2.00 x 3.17 (50.8 x 80.5)	2.00 x 1.00 (50.8 x 25.4)	0.32-0.69 (8.1-17.5)	25 Pair	42-132 Strand	1000
LJSL19-Y3-1		1.00 x 5.45 (25.4 x 138.4)	1.00 x 1.00 (25.4 x 25.4)	0.32-1.42 (8.1-36.1)	25 Pair	42-156 Strand	1000
<b>For PANDUIT® PTR2E Thermal Transfer Printer or comparable desktop printers (Labels supplied on 1" cores)</b>							
TTSL-2*	GMV3	1.00 x 1.50 (25.4 x 38.1)	1.00 x 0.50 (25.4 x 12.7)	0.16-0.32 (4.1-8.1)	4 Pair	2-18 Strand	2500
TTSL-3*	Self-Laminating Vinyl (Indoor)	2.00 x 1.50 (50.8 x 38.1)	2.00 x 0.50 (50.8 x 12.7)	0.32-0.46 (8.1-11.7)	25 Pair	42-48 Strand	1000
TTSL-4*		1.00 x 2.44 (25.4 x 62.0)	1.00 x 1.00 (25.4 x 25.4)				1500
TTSL-5*		2.00 x 2.44 (50.8 x 62.0)	2.00 x 1.00 (50.8 x 25.4)				500
TTSL-54	GMT1	1.00 x 1.50 (25.4 x 38.1)	1.00 x 0.50 (25.4 x 12.7)	0.16-0.32 (4.1-8.1)	4 Pair	2-18 Strand	2500
TTSL-55	Self-Laminating TEDLAR (Indoor/Outdoor)	2.00 x 1.50 (50.8 x 38.1)	2.00 x 0.50 (50.8 x 12.7)	0.32-0.46 (8.1-11.7)	25 Pair	42-48 Strand	1000
TTSL-56		1.00 x 2.44 (25.4 x 62.0)	1.00 x 1.00 (25.4 x 25.4)				1500
TTSL-57		2.00 x 2.44 (50.8 x 62.0)	2.00 x 1.00 (50.8 x 25.4)				500
<b>For PANDUIT PTR3E Thermal Transfer Printer or comparable desktop printers (Labels supplied on 3" cores)</b>							
TTSL2VC3-5*	GMV3	1.00 x 1.50 (25.4 x 38.1)	1.00 x 0.50 (25.4 x 12.7)	0.16-0.32 (4.1-8.1)	4 Pair	2-18 Strand	5000
TTSL3VC3-1	Self-Laminating Vinyl (Indoor)	2.00 x 1.50 (50.8 x 38.1)	2.00 x 0.50 (50.8 x 12.7)	0.32-0.46 (8.1-11.7)	25 Pair	42-48 Strand	1000
TTSL4VC3-5		1.00 x 2.44 (25.4 x 62.0)	1.00 x 1.00 (25.4 x 25.4)				5000
TTSL5VC3-2.5		2.00 x 2.44 (50.8 x 62.0)	2.00 x 1.00 (50.8 x 25.4)				2500
<b>For Desktop Dot-Matrix Printers</b>							
PDL-2*	GMV3	1.00 x 1.44 (25.4 x 36.5)	1.00 x 0.50 (25.4 x 12.7)	0.16-0.30 (4.1-7.6)	4 Pair	2-18 Strand	5000
PDL-3	Self-Laminating Vinyl (Indoor)	2.00 x 1.44 (50.8 x 36.5)	2.00 x 0.50 (50.8 x 12.7)	0.24-0.54 (6.1-13.7)	25 Pair	16-84 Strand	5000
PDL-4		1.00 x 2.44 (25.4 x 62.0)	1.00 x 0.75 (25.4 x 19.1)				1000
PDL-5*		2.00 x 2.44 (50.8 x 62.0)	2.00 x 0.75 (50.8 x 19.1)				1000
PDL-54*	GMT1	1.00 x 1.38 (25.4 x 34.9)	1.00 x 0.50 (25.4 x 12.7)	0.16-0.28 (4.1-7.1)	4 Pair	2-18 Strand	5000
	Self-Laminating TEDLAR (Indoor/Outdoor)						

#### ORDERING INFORMATION:

Order number of labels required, in multiples of Standard Package Quantity.

\*Part numbers shown have white print-on areas. Other colors available. See [page E17](#) for ordering information. Colored labels are not available for ink jet printers.

▲ TEDLAR is the registered trademark of E.I. DuPont Co.