


Front adapters - FLKM 50-PA-AB/1756 - 2296427

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

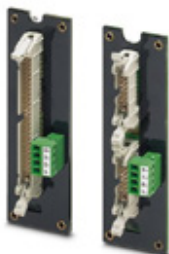


VARIOFACE front adapters, for ControlLogix, max. 1 x 32 channels can be connected, number of positions 50.
The front adapters cannot be pushed into a hood!

The figure shows front adapter for Allen Bradley in design Control-Logix and Honeywell Plant-Scape



Key Commercial Data

Packing unit	1 pc
GTIN	 4 017918 584368
GTIN	4017918584368
Weight per Piece (excluding packing)	39.300 g
Custom tariff number	85366990
Country of origin	Germany
Note	Made to Order (non-returnable)

Technical data

General

Max. permissible operating voltage	25 V AC
	60 V DC
Max. permissible current	1 A (per path)
	8 A (per connection, supply via separate power supply)
Mounting position	any

Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

Standards and Regulations

Connection in acc. with standard	CUL
Standards/regulations	IEC 60664

Front adapters - FLKM 50-PA-AB/1756 - 2296427

Technical data

Standards and Regulations


	IEC 60664A
	DIN VDE 0110
	DIN VDE 0160 (in parts)
Pollution degree	2
Overvoltage category	II

Environmental Product Compliance

	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Circuit diagram

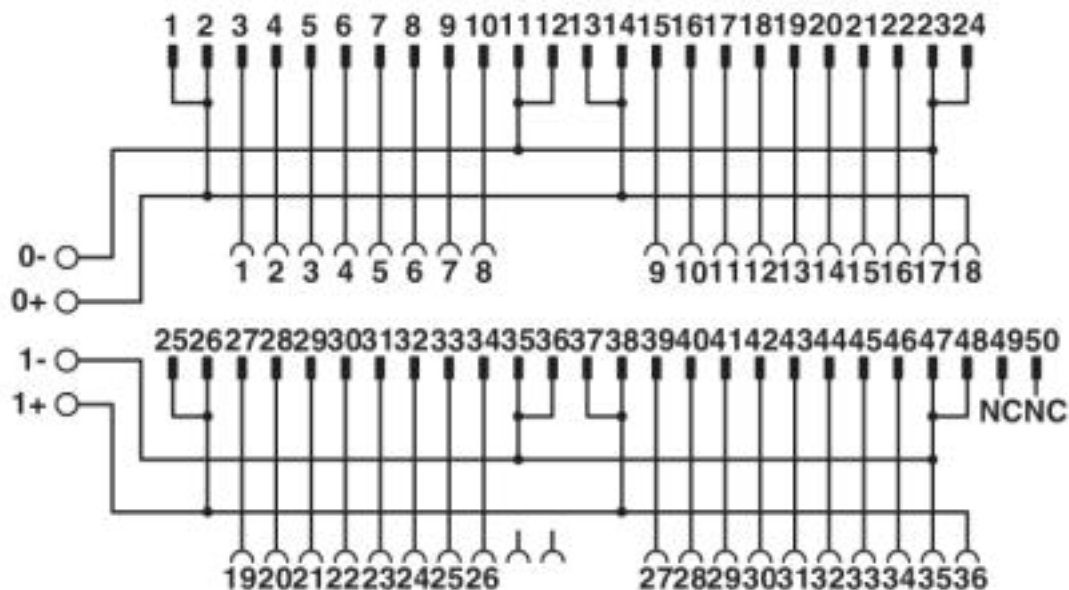

Classifications

eCl@ss

eCl@ss 4.0	27250300
eCl@ss 4.1	27250300
eCl@ss 5.0	27250300
eCl@ss 5.1	27250300
eCl@ss 6.0	27249200
eCl@ss 7.0	27249290
eCl@ss 8.0	27249290

Front adapters - FLKM 50-PA-AB/1756 - 2296427

Classifications

eCl@ss

eCl@ss 9.0	27242292
------------	----------

ETIM

ETIM 4.0	EC002584
ETIM 5.0	EC002584
ETIM 6.0	EC002584
ETIM 7.0	EC002584

UNSPSC

UNSPSC 6.01	30211824
UNSPSC 7.0901	39121421
UNSPSC 11	39121421
UNSPSC 12.01	39121421
UNSPSC 13.2	32151601
UNSPSC 19.0	32151601

Approvals


Approvals


Approvals

UL Recognized / cUL Recognized / EAC / cULus Recognized

Ex Approvals

Approval details

UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 238705
Nominal voltage UN	125 V		
Nominal current IN	1 A		

cUL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 238705
Nominal voltage UN	125 V		
Nominal current IN	1 A		

Front adapters - FLKM 50-PA-AB/1756 - 2296427

Approvals

