

Mounting material - PACT-FAST-MNT-W16-L65 - 2276641

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



The transformer quick-action mechanism enables the lightning-fast mounting of PACT current transformers on the power rail. The installation can be completed easily by hand without the use of tools. Fixing pins: 65 mm, holding latches: 16 mm

RoHS

Key Commercial Data

Packing unit	1 pc
GTIN	 4 046356 659017
GTIN	4046356659017
Weight per Piece (excluding packing)	46.200 g
Custom tariff number	39269097
Country of origin	China

Technical data

Note

Note	The 16 mm wide converter attachment can also be used for larger current transformers if the length of the fixing pins is sufficient.
------	--

Dimensions

Width	16 mm
Depth	65 mm

Ambient conditions

Ambient temperature (operation)	-25 °C ... 120 °C
---------------------------------	-------------------

Connection data

Torque	0.4 Nm
--------	--------


Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Mounting material - PACT-FAST-MNT-W16-L65 - 2276641

Drawings

Dimensional drawing

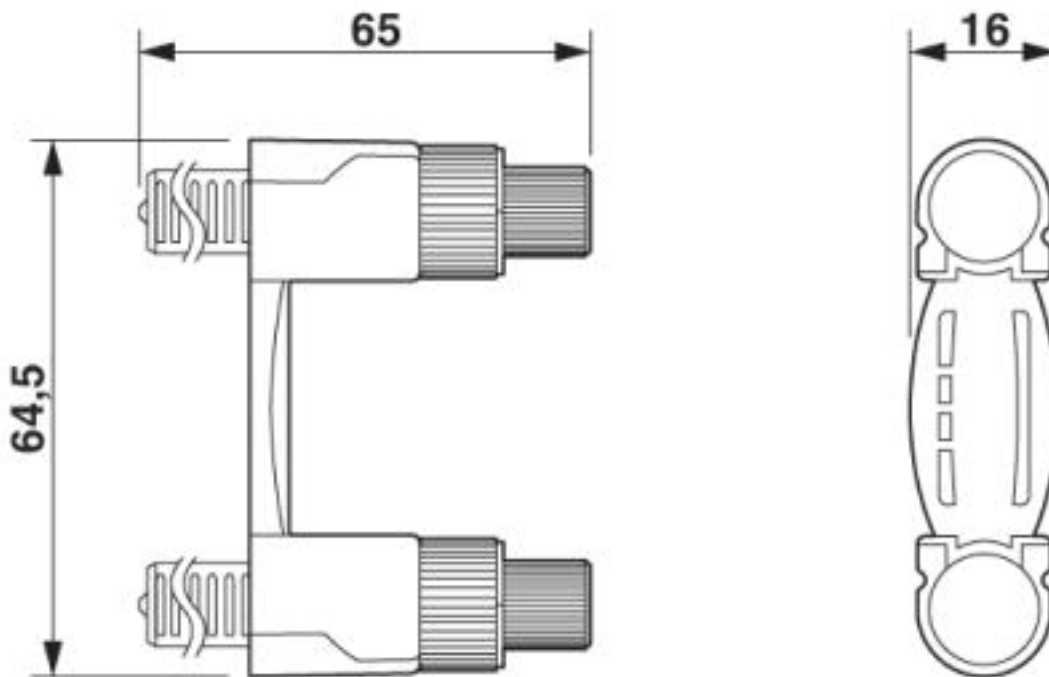

Classifications

eCl@ss

eCl@ss 10.0.1	27219290
eCl@ss 4.0	27210900
eCl@ss 4.1	27210900
eCl@ss 5.0	27210900
eCl@ss 5.1	27210900
eCl@ss 6.0	27149200
eCl@ss 7.0	27149223
eCl@ss 8.0	27219290
eCl@ss 9.0	27219290

ETIM

ETIM 4.0	EC002048
ETIM 5.0	EC002498
ETIM 6.0	EC002498
ETIM 7.0	EC002498

UNSPSC

UNSPSC 6.01	30211501
UNSPSC 7.0901	39121019

Mounting material - PACT-FAST-MNT-W16-L65 - 2276641

Classifications

UNSPSC

UNSPSC 11	39121006
UNSPSC 12.01	39121006
UNSPSC 13.2	39121006

Accessories

Necessary add-on products

Current transformer - PACT MCR-V2- 3015- 60 - 2277271



Window-type current transformer, primary current can be selected between 50...750 A AC; secondary current can be selected as 1 A AC or 5 A AC; accuracy class can be selected as 0.5 or 1; rated power can be selected

Current transformer - PACT MCR-V2-3015- 60- 60-5A-1 - 2277815



Window-type current transformer, 60 A AC primary current; 5 A AC secondary current; accuracy class 1; 1.25 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 75-5A-1 - 2277828



Window-type current transformer, 75 A AC primary current; 5 A AC secondary current; accuracy class 1; 1.25 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 80-5A-1 - 2277831



Window-type current transformer, 80 A AC primary current; 5 A AC secondary current; accuracy class 1; 1.25 VA rated power

Mounting material - PACT-FAST-MNT-W16-L65 - 2276641

Accessories

Current transformer - PACT MCR-V2-3015- 60- 100-5A-1 - 2277064



Window-type current transformer, 100 A AC primary current; 5 A AC secondary current; accuracy class 1; 2.5 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 125-5A-1 - 2277624



Window-type current transformer, 125 A AC primary current; 5 A AC secondary current; accuracy class 1; 3.75 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 150-5A-1 - 2277077



Window-type current transformer, 150 A AC primary current; 5 A AC secondary current; accuracy class 1; 5 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 150-5A-1 - 2277844



Window-type current transformer, 150 A AC primary current; 5 A AC secondary current; accuracy class 1; 3.75 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 200-5A-1 - 2277637



Window-type current transformer, 200 A AC primary current; 5 A AC secondary current; accuracy class 1; 5 VA rated power

Mounting material - PACT-FAST-MNT-W16-L65 - 2276641

Accessories

Current transformer - PACT MCR-V2-3015- 60- 200-5A-1 - 2277857



Window-type current transformer, 200 A AC primary current; 5 A AC secondary current; accuracy class 1; 7.5 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 250-5A-1 - 2277080



Window-type current transformer, 250 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 250-5A-1 - 2277860



Window-type current transformer, 250 A AC primary current; 5 A AC secondary current; accuracy class 1; 7.5 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 300-5A-1 - 2277640



Window-type current transformer, 300 A AC primary current; 5 A AC secondary current; accuracy class 1; 7.5 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 400-5A-1 - 2277093



Window-type current transformer, 400 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Mounting material - PACT-FAST-MNT-W16-L65 - 2276641

Accessories

Current transformer - PACT MCR-V2-3015- 60- 500-5A-1 - 2277653



Window-type current transformer, 500 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 600-5A-1 - 2277103



Window-type current transformer, 600 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Current transformer - PACT MCR-V2-3015- 60- 750-5A-1 - 2277666



Window-type current transformer, 750 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Current transformer - PACT MCR-V2- 6015- 85 - 2277336



Window-type current transformer, primary current can be selected between 200...1600 A AC; secondary current can be selected as 1 A AC or 5 A AC; accuracy class can be selected as 0.5 or 1; rated power can be selected

Current transformer - PACT MCR-V2-6015- 85- 200-5A-1 - 2277873



Window-type current transformer, 200 A AC primary current; 5 A AC secondary current; accuracy class 1; 2.5 VA rated power

Mounting material - PACT-FAST-MNT-W16-L65 - 2276641

Accessories

Current transformer - PACT MCR-V2-6015- 85- 250-5A-1 - 2277886



Window-type current transformer, 250 A AC primary current; 5 A AC secondary current; accuracy class 1; 2.5 VA rated power

Current transformer - PACT MCR-V2-6015- 85- 300-5A-1 - 2277899



Window-type current transformer, 300 A AC primary current; 5 A AC secondary current; accuracy class 1; 2.5 VA rated power

Current transformer - PACT MCR-V2-6015- 85- 400-5A-1 - 2277909



Window-type current transformer, 400 A AC primary current; 5 A AC secondary current; accuracy class 1; 2.5 VA rated power

Current transformer - PACT MCR-V2-6015- 85- 500-5A-1 - 2277912



Window-type current transformer, 500 A AC primary current; 5 A AC secondary current; accuracy class 1; 5 VA rated power

Current transformer - PACT MCR-V2-6015- 85- 600-5A-1 - 2277925



Window-type current transformer, 600 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Mounting material - PACT-FAST-MNT-W16-L65 - 2276641

Accessories

Current transformer - PACT MCR-V2-6015- 85- 750-5A-1 - 2277938



Window-type current transformer, 750 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Current transformer - PACT MCR-V2-6015- 85- 800-5A-1 - 2277941



Window-type current transformer, 800 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Current transformer - PACT MCR-V2-6015- 85-1000-5A-1 - 2277954



Window-type current transformer, 1000 A AC primary current; 5 A AC secondary current; accuracy class 1; 15 VA rated power

Current transformer - PACT MCR-V2-6015- 85-1250-5A-1 - 2277967



Window-type current transformer, 1250 A AC primary current; 5 A AC secondary current; accuracy class 1; 15 VA rated power

Current transformer - PACT MCR-V2-6015- 85-1500-5A-1 - 2277970



Window-type current transformer, 1,500 A AC primary current; 5 A AC secondary current; accuracy class 1; 15 VA rated power

Mounting material - PACT-FAST-MNT-W16-L65 - 2276641

Accessories

Current transformer - PACT MCR-V2-6015- 85-1600-5A-1 - 2277983



Window-type current transformer, 1,600 A AC primary current; 5 A AC secondary current; accuracy class 1; 15 VA rated power

Current transformer - PACT MCR-V2- 6315- 95 - 2277307



Window-type current transformer, primary current can be selected between 200.0.2500 A AC; secondary current can be selected as 1 A AC or 5 A AC; accuracy class can be selected as 0.5 or 1; rated power can be selected

Current transformer - PACT MCR-V2-6315- 95- 800-5A-1 - 2277213



Window-type current transformer, 800 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Current transformer - PACT MCR-V2-6315- 95-1000-5A-1 - 2277226



Window-type current transformer, 1000 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Current transformer - PACT MCR-V2-6315- 95-1250-5A-1 - 2277239



Window-type current transformer, 1,250 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Mounting material - PACT-FAST-MNT-W16-L65 - 2276641

Accessories

Current transformer - PACT MCR-V2-6315- 95-1500-5A-1 - 2277242



Window-type current transformer, 1,500 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power

Current transformer - PACT MCR-V2-6315- 95-1600-5A-1 - 2277255



Window-type current transformer, 1,600 A AC primary current; 5 A AC secondary current; accuracy class 1; 10 VA rated power
