


PRODUCT-DETAILS

# SR2-SRN10830VK

## ENCLOSURE GLASS DOOR 1000X800X300 7035

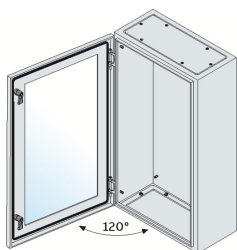

### General Information

Extended Product Type	SR2-SRN10830VK
Product ID	SRN10830VK
EAN	8015646753816
Catalog Description	ENCLOSURE GLASS DOOR 1000X800X300 7035
Long Description	Enclosure with glazed door 1000x800x300mm (HxWxD)

### Ordering

EAN	8015646753816
Minimum Order Quantity	1 piece
Customs Tariff Number	85381000

### Dimensions

Product Net Width	800 mm
Product Net Height	1000 mm
Product Net Depth / Length	300 mm
Product Net Weight	36.7 kg

### Container Information

Package Level 1 Units	1 piece
Package Level 1 Width	0.825 m
Package Level 1 Height	0.320 m
Package Level 1 Depth / Length	1.025 m
Package Level 1 Gross Weight	37.200 kg
Package Level 1 EAN	8015646753816

---

### Additional Information

Color	Grey
Construction Material	Galvanized steel
Cover Plate Type	Door
Degree of Protection	IP65
Housing Material	Steel
Interior Depth	283,5 mm
Mounting Type	Surface mounted (plaster)
Order Multiple	1 piece
Product Main Type	SR2 Enclosures
Product Name	Control and Automation Board
Protection Class	Grounded
Suitable for Product Class	SR2
Surface Finishing	Powder coating

---

### Certificates and Declarations (Document Number)

Data Sheet, Technical Information	1STC804013D0203
Declaration of Conformity - CE	not applicable
Environmental Information	1STC804013D0203
Instructions and Manuals	1STM6041230001
RoHS Information	1STC860027

---

### Classifications

ETIM 4	EC000200 - Enclosure for control circuit devices
ETIM 5	EC000200 - Enclosure for control circuit devices
ETIM 6	EC000058 - Empty cabinet
ETIM 7	EC000058 - Empty cabinet
Object Classification Code	U
WEEE Category	Product Not in WEEE Scope

---

### Categories

Low Voltage Products and Systems → Enclosures → General Purpose Enclosures

