

Corrugated tube screw connection - HC-B-GCA-M32-PLRBK - 1412022

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



EVO corrugated pipe screw connection, size: M32, protection class: IP66, plastic



Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4046356948654
Weight per Piece (excluding packing)	68.970 g
Custom tariff number	39269097
Country of origin	Poland

Technical data

General

Material	PA
Sealing material	Neoprene (Sleeve seal)
Thread type on seal side	M32
Tightening torque, union nut	7.50 Nm
Color	black
Assembly instructions	Please observe the installation note provided for the WP-PA HF-HB.....BK corrugated pipe

Dimensions

Outside diameter	34.50 mm
External cable diameter	15 mm ... 21 mm

Ambient conditions

Degree of protection (IP)	IP66
Ambient temperature (operation)	-40 °C ... 115 °C

Environmental Product Compliance

Corrugated tube screw connection - HC-B-GCA-M32-PLRBK - 1412022


Technical data

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

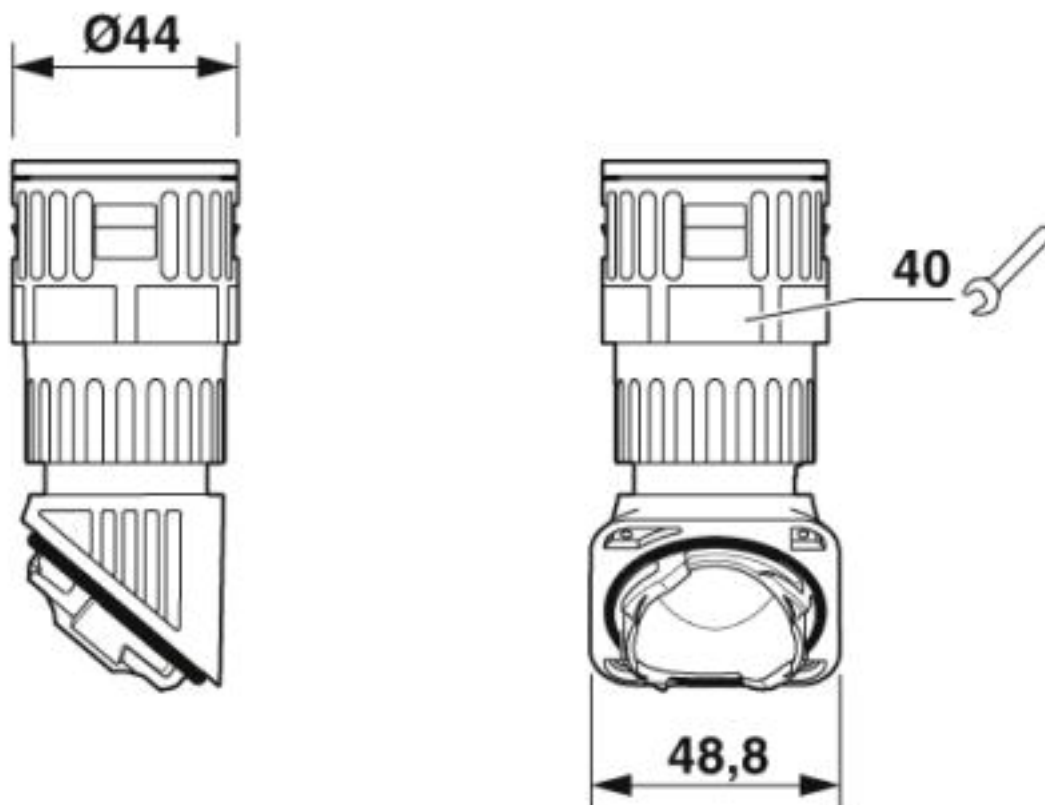

Dimensional drawing

Classifications

eCl@ss

eCl@ss 4.0	27140800
eCl@ss 4.1	27140800
eCl@ss 5.0	27143400
eCl@ss 5.1	27143400
eCl@ss 6.0	27261200
eCl@ss 7.0	27439205
eCl@ss 8.0	27439205
eCl@ss 9.0	27430308

Corrugated tube screw connection - HC-B-GCA-M32-PLRBK - 1412022

Classifications

ETIM

ETIM 4.0	EC000441
ETIM 5.0	EC000441
ETIM 6.0	EC002908
ETIM 7.0	EC002908

UNSPSC

UNSPSC 13.2	39121421
UNSPSC 18.0	39121421
UNSPSC 19.0	39121421
UNSPSC 20.0	39121421
UNSPSC 21.0	39121421

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		RU C- DE.AI30.B.01102
-----	--	--------------------------

Accessories

Accessories

Corrugated pipe

Protective hose - WP-PA HF 34,5 BK - 3241088



Polyamide protective hose, inflammability class V0, UV resistant, 1 Pcs. / Pkt. = roll à 25 m

