

## Replacement part - HC-STA-B06-SL-PLBK - 1412591

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Single locking latch for B6 housing, HC-EVO....AL and HC-STA....AL



### Key Commercial Data

Packing unit	1 pc
GTIN	 4 046356 986571
GTIN	4046356986571
Weight per Piece (excluding packing)	16.500 g
Custom tariff number	85389099
Country of origin	Poland

### Technical data

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

#### General

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------


#### Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

### Drawings

## Replacement part - HC-STA-B06-SL-PLBK - 1412591

Dimensional drawing

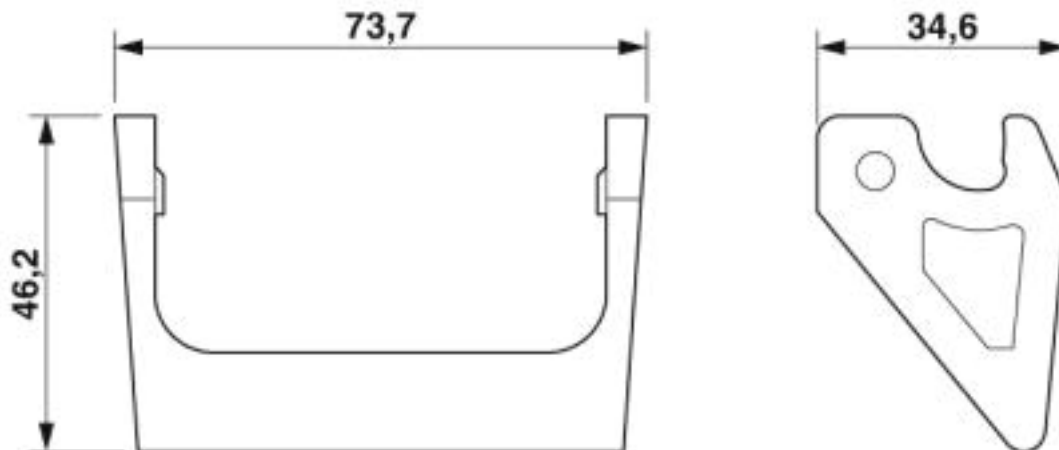

Dimensional drawing

### Classifications

#### eCl@ss

eCl@ss 10.0.1	27440192
eCl@ss 4.0	27378000
eCl@ss 4.1	27378000
eCl@ss 5.0	27379100
eCl@ss 5.1	27379100
eCl@ss 6.0	27379200
eCl@ss 7.0	27379201
eCl@ss 8.0	27379201
eCl@ss 9.0	27440192

#### ETIM

ETIM 4.0	EC002498
ETIM 5.0	EC002498
ETIM 6.0	EC000761
ETIM 7.0	EC000761

#### UNSPSC

UNSPSC 13.2	39131505
UNSPSC 18.0	39121421
UNSPSC 19.0	39121421
UNSPSC 20.0	39121421
UNSPSC 21.0	39121421

### Approvals

#### Approvals

# Replacement part - HC-STA-B06-SL-PLBK - 1412591

## Approvals

---

Approvals

EAC / DNV GL

---

Ex Approvals

---

## Approval details

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------

DNV GL		<a href="https://approvalfinder.dnvgl.com/">https://approvalfinder.dnvgl.com/</a>	TAE000037S
--------	---	---	------------

---