

Electronic housing - DCS 7 M C O C 1 7035 - 2203183

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Display housing, 7", light gray, central window, front level, consisting of two half shells, four front plates with screws

Your advantages

- ✔ Item belongs to the DCS product range
- ✔ Display housings for mobile and stationary operator panels
- ✔ Integration of TFT display and membrane keypads
- ✔ Degree of protection: up to IP54
- ✔ Temperature range: -20°C to +50°C
- ✔ Shock-resistant ABS plastic
- ✔ Flammability rating UL 94-V0



Key Commercial Data

Packing unit	2 pc
GTIN	 4 055626 378374
GTIN	4055626378374
Weight per Piece (excluding packing)	290.000 g
Custom tariff number	39269097
Country of origin	Germany

Technical data

Item properties

Type	DCS 7 M C O C 1 7035
Order No.	2203183
Housing type	Display housing
Battery compartment	no
Wall fastening	no
Ventilation openings present	no

Electronic housing - DCS 7 M C O C 1 7035 - 2203183

Technical data

Measurements

Width [w]	224 mm
Height [h]	157 mm
Depth [d]	40 mm
Diagonal	7 in. (Window for display)
Dimensions	154.4 mm x 93.4 mm (Window for display, center position)
Front with faceplate	top, 2 x (62.8 mm x 21.8 mm)
	left, 1 x (102.95 mm x 20 mm)
	right, 1 x (102.95 mm x 20 mm)

Material specifications

Flammability rating according to UL 94	V0
Housing material	ABS

Packaging information

Pieces per package	2
Denomination packing units	Pcs.


Standards and regulations

Flammability rating according to UL 94	V0
--	----

Drawings

Electronic housing - DCS 7 M C O C 1 7035 - 2203183

Dimensional drawing

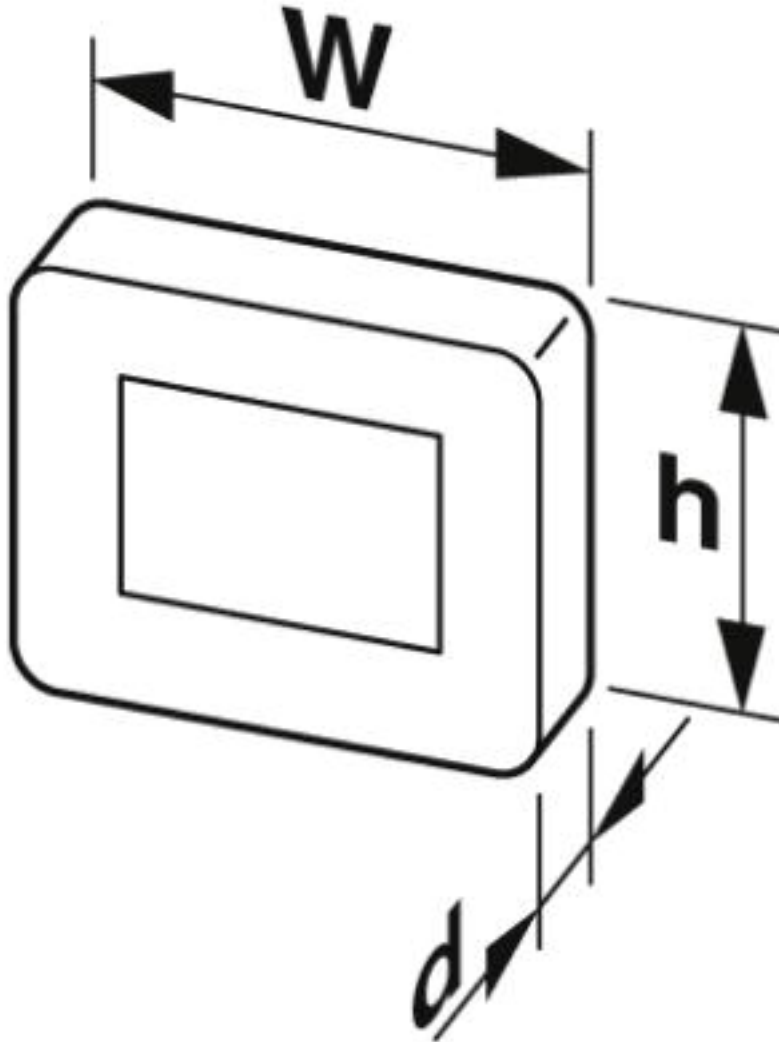

Classifications

eCl@ss

eCl@ss 5.1	27180506
eCl@ss 6.0	27180800
eCl@ss 7.0	27182702
eCl@ss 8.0	27182702
eCl@ss 9.0	27182702

ETIM

ETIM 5.0	EC001031
ETIM 6.0	EC001031
ETIM 7.0	EC001031

Electronic housing - DCS 7 M C O C 1 7035 - 2203183

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		B.01742
-----	--	---------

Accessories

Accessories

Screwdriver tools

Philips screwdriver - SF-PH 0-60 - 1212558



Screwdriver, PH crosshead, size: PH 0 x 60, 2-component grip, with non-slip grip

Additional products

Seal - DCS 5,7-7,0 SEAL - 2203584



Sealing set, including cord and O-rings

Display - D T 7,0 WVGA P - 2203551



TFT module 7", 800 x 480 pixels, transmissive/color, LED backlight, white, interface: parallel, 24 bit, operating temperature: -20 °C ... 70 °C

Electronic housing - DCS 7 M C O C 1 7035 - 2203183

Accessories

Mounting set - DCS D-FIX 7,0 - 2203830

Mounting set including plate and screws, for display mounting



Seal - DCS D-SEAL 3,0MM - 2203749

Sealing strip, self-adhesive, for displays of the DCS housing series (roll: 100 m)



Washer/ring - DCS 7,0 WIN 1,5 CLEAR - 2203596

Acrylic glass, satin-finished, frame printed black, for display 800x480

