

DIN rail, unperforated - NS 35/15 ZN UNPERF 3000MM - 3240065


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



DIN rail, unperforated, Standard profile, width: 35 mm, height: 15 mm, similar to EN 60715, material: Steel, galvanized, length: 3000 mm



Key Commercial Data

Packing unit	1 pc
Minimum order quantity	200 pc
GTIN	 4 046356 756099
GTIN	4046356756099
Weight per Piece (excluding packing)	1,962.000 g
Custom tariff number	72166190
Country of origin	Germany
Note	Made to Order (non-returnable)

Technical data

Dimensions

Length (b)	3000 mm
Width (a)	35 mm
Height (c)	15 mm
Drill hole spacing	0.00 mm

General



Material	Steel
Coating	galvanized
Test standard	similar to EN 60715

Standards and Regulations

Test standard	similar to EN 60715
Connection in acc. with standard	IEC / EN

DIN rail, unperforated - NS 35/15 ZN UNPERF 3000MM - 3240065

Drawings

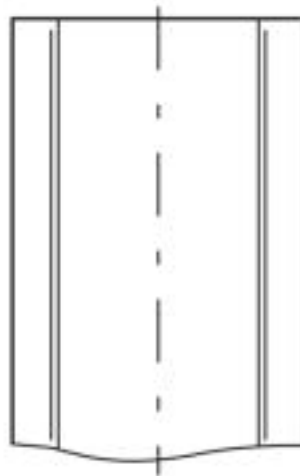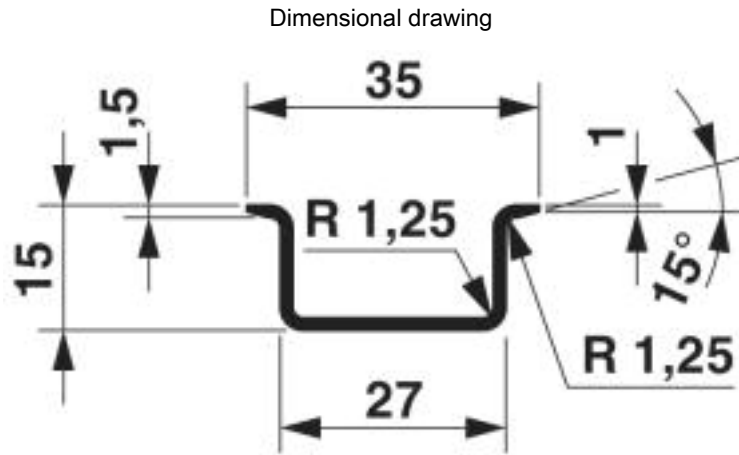

Classifications

eCl@ss

eCl@ss 4.0	23150300
eCl@ss 4.1	23150300
eCl@ss 5.0	27141100
eCl@ss 5.1	27141100
eCl@ss 6.0	27400600
eCl@ss 7.0	27400602
eCl@ss 8.0	27400602
eCl@ss 9.0	27400602

DIN rail, unperforated - NS 35/15 ZN UNPERF 3000MM - 3240065

Classifications

ETIM

ETIM 2.0	EC001285
ETIM 3.0	EC001285
ETIM 4.0	EC000212
ETIM 5.0	EC000212
ETIM 6.0	EC001285
ETIM 7.0	EC001285

UNSPSC

UNSPSC 6.01	30212109
UNSPSC 7.0901	39121708
UNSPSC 11	39121708
UNSPSC 12.01	39121708
UNSPSC 13.2	39121708
UNSPSC 18.0	39121708
UNSPSC 19.0	39121708
UNSPSC 20.0	39121708
UNSPSC 21.0	39121708