


PRODUCT-DETAILS

XT2 P FP 3p EF

XT2 P FP 3p EF

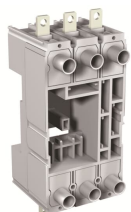

General Information

Extended Product Type	XT2 P FP 3p EF
Product ID	1SDA068187R1
EAN	8015644020842
Catalog Description	XT2 P FP 3p EF
Long Description	FIXED PART PLUG-IN FOR C.BREAKER TMAX THREE-POLE WITH EXTENDED FRONT TERMINALS XT2

Ordering

E-Number (Sweden)	3182031
EAN	8015644020842
Minimum Order Quantity	1 piece
Customs Tariff Number	85389099

Dimensions

Product Net Width	120 mm
Product Net Height	180 mm
Product Net Depth / Length	225 mm
Product Net Weight	0.9 kg

Container Information

Package Level 1 Units	1 piece
Package Level 1 Width	120 mm
Package Level 1 Height	180 mm
Package Level 1 Depth / Length	225 mm
Package Level 1 Gross Weight	1 kg
Package Level 1 EAN	8015644020842

Additional Information

Configuration Type	Loose or configurable
Number of Poles	3
Order Multiple	1 piece
Product Main Type	Accessories for Tmax XT
Product Name	Accessory
Product Type	FP
Rated Frequency (f)	50 / 60 Hz
Rated Impulse Withstand Voltage (U _{imp})	8 kV
Rated Insulation Voltage (U _i)	1000 V
Rated Operational Voltage	690 V AC 500 V DC
Standards	IEC 60947
Sub-type	XT2
Suitable For	XT2
Terminal Connection Type	Plug-In Circuit-Breakers Front Extended
Version	P

Certificates and Declarations (Document Number)

Data Sheet, Technical Information	1SDC210100D0204 1SDC210099D0204
Instructions and Manuals	1SDH000721R0002

Classifications

ETIM 6	EC002043 - Chassis part power circuit breaker
ETIM 7	EC002043 - Chassis part power circuit breaker
Object Classification Code	Q
UNSPSC	39120000
WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)

Categories

Low Voltage Products and Systems → Circuit Breakers → Moulded Case Circuit Breakers → Tmax XT

