


PRODUCT-DETAILS

# XT2 P FP 4p EF

# XT2 P FP 4p EF

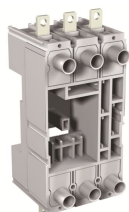

## General Information

Extended Product Type	XT2 P FP 4p EF
Product ID	1SDA068190R1
EAN	8015644020866
Catalog Description	XT2 P FP 4p EF
Long Description	FIXED PART PLUG-IN FOR C.BREAKER TMAX FOUR-POLE WITH EXTENDED FRONT TERMINALS XT2

## Ordering

E-Number (Sweden)	3182039
EAN	8015644020866
Minimum Order Quantity	1 piece
Customs Tariff Number	85389099

## Dimensions

Product Net Width	120 mm
Product Net Height	180 mm
Product Net Depth / Length	225 mm
Product Net Weight	1.12 kg

---

**Container Information**


---

Package Level 1 Units	1 piece
Package Level 1 Width	120 mm
Package Level 1 Height	180 mm
Package Level 1 Depth / Length	225 mm
Package Level 1 Gross Weight	1.22 kg
Package Level 1 EAN	8015644020866

---



---

**Additional Information**


---

Configuration Type	Loose or configurable
Number of Poles	4
Order Multiple	1 piece
Product Main Type	Accessories for Tmax XT
Product Name	Accessory
Product Type	FP
Rated Frequency (f)	50 / 60 Hz
Rated Impulse Withstand Voltage (U <sub>imp</sub> )	8 kV
Rated Insulation Voltage (U <sub>i</sub> )	1000 V
Rated Operational Voltage	690 V AC 500 V DC
Standards	IEC 60947
Sub-type	XT2
Suitable For	XT2
Terminal Connection Type	Plug-In Circuit-Breakers Front Extended
Version	P

---



---

**Certificates and Declarations (Document Number)**


---

Data Sheet, Technical Information	1SDC210100D0204 1SDC210099D0204
Instructions and Manuals	1SDH000721R0002

---



---

**Classifications**


---

ETIM 6	EC002043 - Chassis part power circuit breaker
ETIM 7	EC002043 - Chassis part power circuit breaker
Object Classification Code	Q
UNSPSC	39120000
WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)

---



---

**Categories**


---

Low Voltage Products and Systems → Circuit Breakers → Moulded Case Circuit Breakers → Tmax XT

