
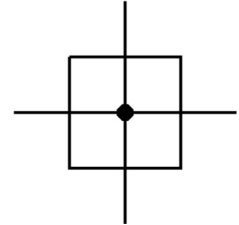


Distributor block MS4-FRM-FRZ

Part number: 549336

FESTO

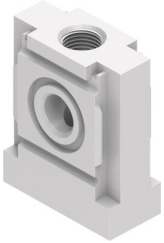

Data sheet

Feature	Value
Type code	MS4-FRZ
Mounting position	Any
Design	Branching module
Symbol	00991510
Operating pressure	0 bar ... 14 bar
Standard nominal flow rate in main flow direction 1 -> 2	4050 l/min
Standard nominal flow rate outlet at top	3250 l/min
Standard nominal flow rate outlet down	2900 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Certification	c UL us - Recognized (OL)
Product weight	60 g
Pneumatic connection 3	G1/4
Pneumatic connection 4	G1/4
Note on materials	RoHS-compliant Free of copper and PTFE
Housing material	Die-cast aluminum