


25

P 129 S





Modular connectors

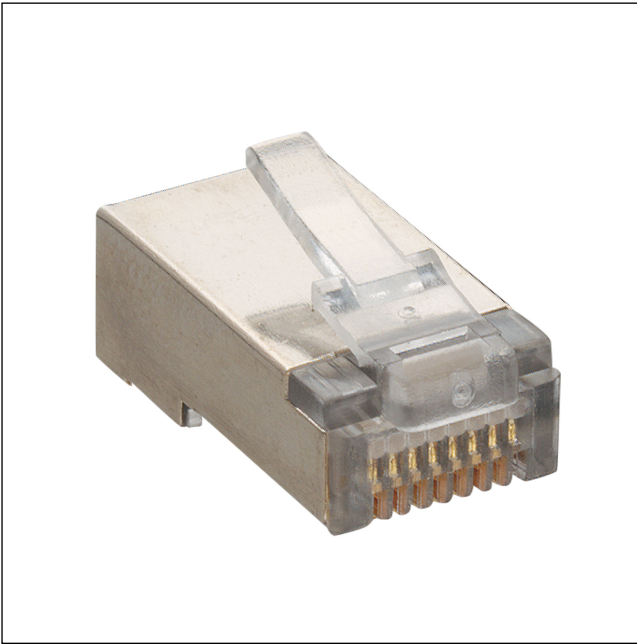

Modular plug, 8p8c (RJ45), with locking latch and shielding, piercing technology

25

P 129 S

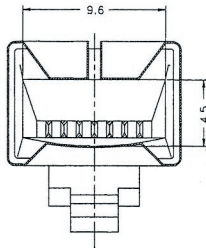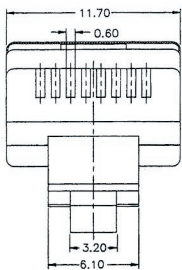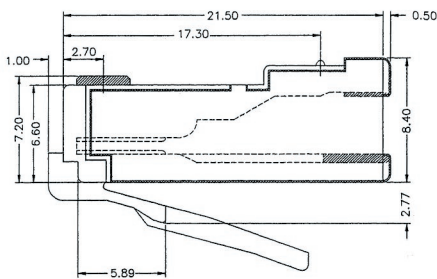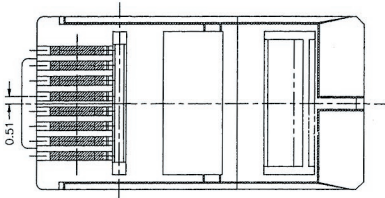

Environmental conditions

Temperature range -40 °C/+125 °C

Materials

Insulating body PC, V-2 according to UL94
Contact CuSn, pre-nickel and gold-plated

Connectable conductors for piercing area

Construction round cable

Electrical data (at T_{amb} 20 °C)

Rated current ≤ 2 A
Rated voltage 250 V
Rated impulse voltage 1 kV
Insulation resistance ≥ 500 MΩ

Associated products

Counterparts
 ☞ 2531 01 ☞ 2541 01 ☞ P 133
 ☞ P 136 ☞ P 137 S

Accessories
 ☞ 2532 01

Harnessing equipment
 ☞ ZP25-2

25

P 129 S

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
P 129 S	8	100	1000

Packaging:
in a tray