



MASTER LED candles and lusters

MASTER LEDlustre DT 4-25W E14 P48 CL

Delivering incandescent-like sparkling light effects, MASTER LED candles and lusters are ideal for general and decorative lighting in the hospitality industry as well as in home environments. Mounted in full view in chandeliers, wall scones or modern luminaires, the clear or frosted glass candles and lusters fit all existing fixtures with an E14, B15, B22 or E27 socket, and enhance the aesthetic appeal of the chandelier or luminaire both when on and off, with their unique, eye-catching lens design. They produce a beautiful sparkling warm light that delivers huge energy savings and minimizes maintenance cost.

Product data

General Information		Operating and Electrical	
Cap-Base	E14 [E14]	Input Frequency	50 to 60 Hz
EU RoHS compliant	Yes	Power (Nom)	4 W
Nominal Lifetime (Nom)	25000 h	Lamp Current (Nom)	25 mA
Switching Cycle	50000X	Wattage Equivalent	25 W
Technical Type	4-25W	Starting Time (Nom)	0.5 s
		Warm Up Time to 60% Light (Nom)	instant full light
Light Technical		Power Factor (Nom)	0.7
Color Code	822-827 [tunable warm white]	Voltage (Nom)	220-240 V
Luminous Flux (Nom)	250 lm		
Color Designation	Warm White (WW)	Temperature	
Correlated Color Temperature (Nom)	- K	T-Case Maximum (Nom)	85 °C
Luminous Efficacy (rated) (Nom)	65 lm/W		
Color Consistency	<6	Controls and Dimming	
Color Rendering Index (Nom)	80	Dimmable	Yes
LLMF At End Of Nominal Lifetime (Nom)	70 %		

MASTER LED candles and lusters

Mechanical and Housing

Bulb Finish Clear

Approval and Application


Energy Efficiency Label (EEL) A+
 Suitable For Accent Lighting No
 Energy Consumption kWh/1000 h 4 kWh

Product Data

Full product code 871869645378000

Order product name	MASTER LEDlustre DT 4-25W E14 P48 CL
EAN/UPC - Product	8718696453780
Order code	929001140002
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001140002
Net Weight (Piece)	0.072 kg

Dimensional drawing

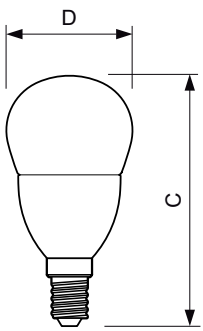


LED DT 4-25W E14 P48 CL


Product

MASTER LEDlustre DT 4-25W E14 P48 CL

Photometric data

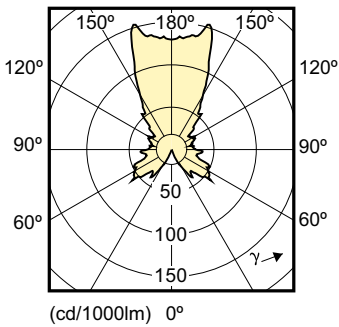

SDLD_LEDLSR_0023-Light distribution diagram

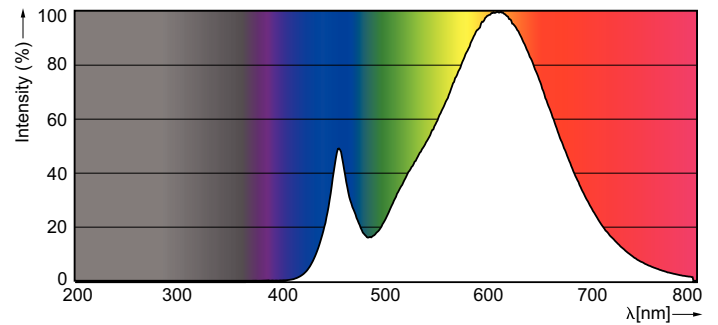

MASTER LED candles and lusters

