


TECHNICAL DATA SHEET

Part#: 2629

Pliers - Small Bent Nose -★★- SS

The 2629 two star small 60° bent nose plier has an overall length of 4.75". It is made of stainless steel and features dual leaf springs for smooth action. The grips are soft cushioned foam and are ESD safe (10^{10} ohms/sq).

- Precision Level ★★
- Material SS (AISI 440)
- Surface Resistivity 10^{10} ohms/sq
- Shape Bent Nose
- Group Pliers
- Tip Size (CTM) .02" (.5mm) x .03" (.75mm)
- Jaw Angle 60°
- Jaw Length .75" (18.75mm)
- Body Width 0.375" (9.38mm)
- Body Height 0.25" (6.25mm)
- OAL 4.75" (118.75mm)
- Weight (OZ) 3.5
- UPC 662847008498
- Schedule B 8203.20.60.30
- ECCN EAR99
- UNSPSC Code 27112128
- Country of Origin Pakistan

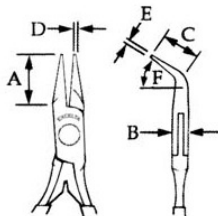

2629 Bent Nose Pliers
Smooth Jaw

- A= .750"
- B= .235"
- C= .300"
- D= .060"
- E= .060"
- F= 30 degrees