ABS Plastic Instrument Enclosures

multicomp PRO
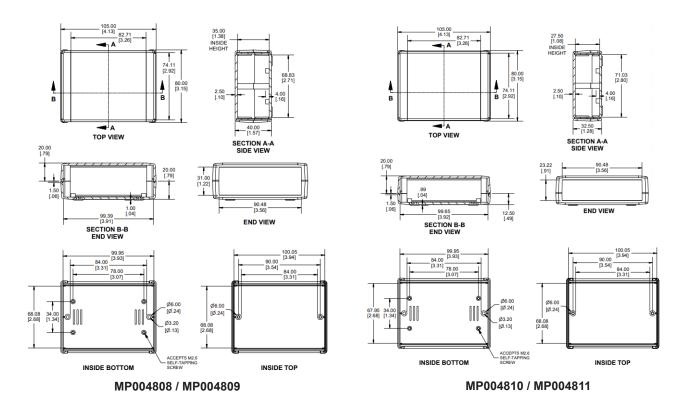
RoHS Compliant

MP004809

MP004813

Features

- Designed to house P.C. boards - for instrument use.
- Molded in light grey or translucent black general purpose ABS plastic with a light texture (front & rear panels are smooth). Material carries a UL flammability rating of UL94 HB.
- Two-part clam shell construction. Bottom half includes molded in standoffs for easy P.C. board installation. Larger enclosures also include P.C. board standoffs on the top half (see photo tables for details). Four short M3 screws included
- Front & rear panels are interchangeable and easily removable for modifications.
- Tongue and groove construction provides protection against dust & water. Designed to meet IP43.
- Includes two (or four) assembly screws (depending on size).
- All units are secured with M3 Philips machine screws, threaded into integral brass bushings. Perfect for applications when repetitive assembly and disassembly are required.
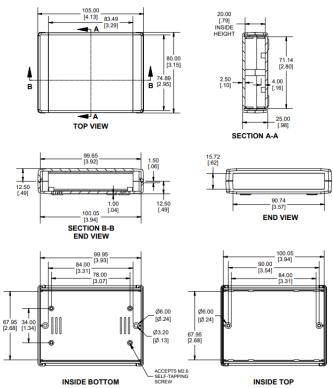- Options include replacement IR translucent or aluminium panels.

MP004808 / MP004809

MP004810 / MP004811

Dimensions : Millimetres (Inches)

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Page <1>   30/07/20   V1.0

ABS Plastic Instrument Enclosures

TOP VIEW

SECTION A-A

SECTION B-B
END VIEW

END VIEW

INSIDE BOTTOM

INSIDE TOP

ACCEPTS M2.6
SELF-TAPPING
SCREW

MP004812 / MP004813

Dimensions : Millimetres (Inches)

Folding Foot Kit

Instrument ABS Plastic Enclosures
Folding Feet Kit
MC001276

Part Number Beige	Part Number Translucent Black	Length	Width	Enclosure Depth (Assembled)
MP004808	MP004809			1.57
MP004810	MP004811	4.13	3.15	1.30
MP004812	MP004813			0.98

Dimensions : Inches

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO