


## Digital Calipers

**Roebuck**

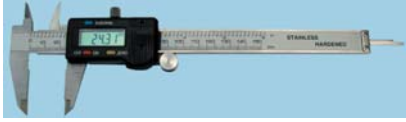

Calipers have hardened stainless steel frame and measuring jaws, depth rod, thumbroll adjustment and knurled locking screw. 3 button operation: On/Off: Inch/Metric conversion. Zero in any position.

### Accuracy

$\pm 0.02\text{mm}$   $\times$  100mm

$\pm 0.03\text{mm}$   $\times$  100 - 200mm

$\pm 0.04\text{mm}$   $\times$  200 - 300mm

489576

Capacity (mm)	Capacity (in)	Resolution	External Jaw	Internal Jaw	Order Code	Price Each
150	6	0.01mm/0.0005in	40mm	18mm	<b>137-5863</b>	
200	8	0.01mm/0.0005in	50mm	20mm	<b>137-5864</b>	
300	12	0.01mm/0.0005in	60mm	20mm	<b>137-5865</b>	