








S SERIES



TYPE No.	Rated Functioning Temperature (°C)	Cut-off Temperature (°C)	Holding Temperature (°C)	Maximum Temperature Limit (°C)	Electrical Ratings		UL 	CSA 	VDE 	TÜV 	BEAB 	MITI 
					Ampere (A)	Voltage (Vac)						
S1	102	98±2	76	200	1	250	●	●	●	●	●	33-265
					1.5	125	●	●	●	●	●	
S2	115	112±3	89	200	1	250	●	●	●	●	●	33-586
					1.5	125	●	●	●	●	●	
S3	130	126±2	102	200	1	250	●	●	●	●	●	33-266
					1.5	125	●	●	●	●	●	
S4	133	130±3	108	200	1	250	●	●	●	●	●	33-266
					1.5	125	●	●	●	●	●	
S5	150	145±2	123	200	1	250	●	●	●	●	●	33-202
					1.5	125	●	●	●	●	●	

UL: E50082, CSA: LR57404, VDE: Ref. No. 9230-4510-1021, TÜV: R9151176, BEAB: CAL. 0036

●=Approved ○=Not approved

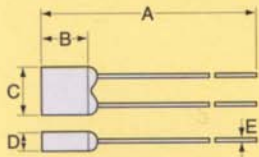

Dimensions(mm)	(A)	(B)	(C)	(D)	(E)
Regular	55±3	4.0±0.5	5.2±0.5	2.2±0.3	0.53±0.02
Long	70±3	4.0±0.5	5.2±0.5	2.2±0.3	0.53±0.02