


## Data Sheet

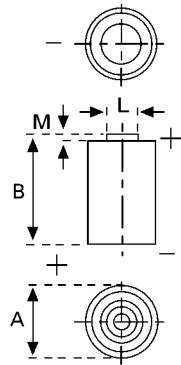

**Type Number** ..... 6215  
**Designation IEC** ..... CR 17345  
**System** ..... Li-Manganese dioxide / Organic Electrolyte

**UL Recognition:**..... MH13654.(N)  
**Nominal Voltage** ..... 3 V  
**Typical Capacity C** ..... 1500 mAh  
 Load 200 Ohm, at 20°C down to 2 V

**Weight (approx.)** ..... 16 g  
**Volume** ..... 7 ccm  
**Coding**..... Date of Manufacturing Quarter / Year

**Temperature Ranges**

	min	max.
Storage .....	-30°C	65 °C
Discharge .....	-20°C	65°C

**Dimensions**

	min	max.
Diameter (A) .....	16	17
Height (B) .....	32,4	33,9
Shoulder Diameter[L].....	6,1	
Shoulder Height [M].....	1	

**Segment** ..... Electronic

**Main Applications** ..... Photo  
 Electronic Devices

### Typical Capacities (at 20°C)

Discharge Type	Load	End Voltage:	2.0 V
Continuous 24h/d,7d/w	200 Ω	Time:	108 h
		Capacity [mAh]:	1500
		Energy [mWh]:	4190