



Datasheet

IEC Glassfibre Exposed Welded Tip Thermocouples with Miniature Thermocouple Plug

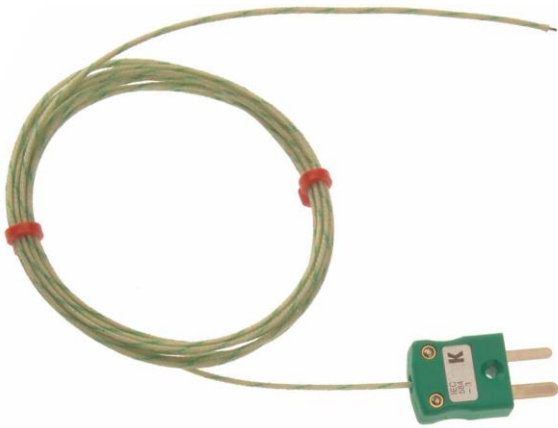

Type 'K'

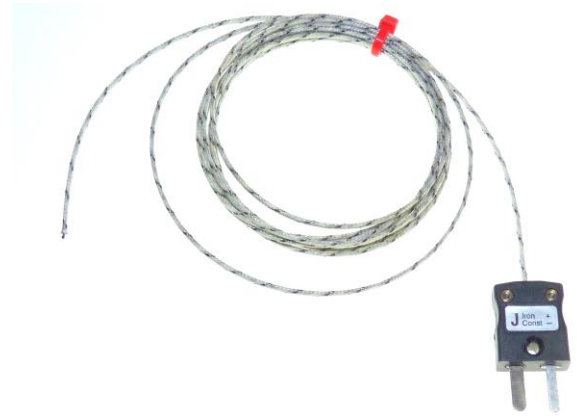

Type 'J'

- Thermocouple types K & J
- Fast response, welded exposed junction
- Various lengths of glassfibre insulated flat pair cable
- Good temperature resistance (not suitable in fluids)
- 1/0.3mm conductors
- 'Re-Wireable' miniature flat pin plug
- Temperature range -60°C to +350°C (short periods up to 400°C)
- Tolerance to IEC 584 Class 2
- Colour code to IEC 584-3
- Ideal for test & development applications

T/C Type	Conductors	Length	Termination	+Positive tail wire	-Negative tail wire	Order Code
'K'	1/0.3mm	1 metres	Mini plug	Green	White	XF-1211-FAR
'K'	1/0.3mm	5 metres	Mini plug	Green	White	XF-1208-FAR
'K'	1/0.3mm	10 metres	Mini plug	Green	White	XF-1209-FAR
'J'	1/0.3mm	1 metres	Mini plug	Black	White	XF-1513-FAR
'J'	1/0.3mm	2 metres	Mini plug	Black	White	XF-1204-FAR
'J'	1/0.3mm	5 metres	Mini plug	Black	White	XF-1514-FAR
'J'	1/0.3mm	10 metres	Mini plug	Black	White	XF-1515-FAR