

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1601126001](#)
Status: **Active**
Overview: [MX150 Sealed and Unsealed Connector System](#)
Description: MX150 Hybrid Mat-Sealed Male Connector Assembly, Dual Row, 12 Circuits, UL 94V-0, Keying Option A, Black

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification 1601110001-PS-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Application Specification 1601110001-AS-000 \(PDF\)](#)

General

Product Family	Crimp Housings
Series	160112
Application	Power, Wire-to-Wire
More Detailed Tech Information	http://uscar.org/guest/teams/10/Electrical-Wiring-Component-Applications -Partnership
Overview	MX150 Sealed and Unsealed Connector System
Polarization	A
Product Name	MX150
UPC	889056813655


Physical

Circuits (maximum)	12
Color - Resin	Black
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	22.682/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +125°C

Material Info

Reference - Drawing Numbers

Application Specification	1601110001-AS-000
Product Specification	1601110001-PS-000
Sales Drawing	1601120000-000

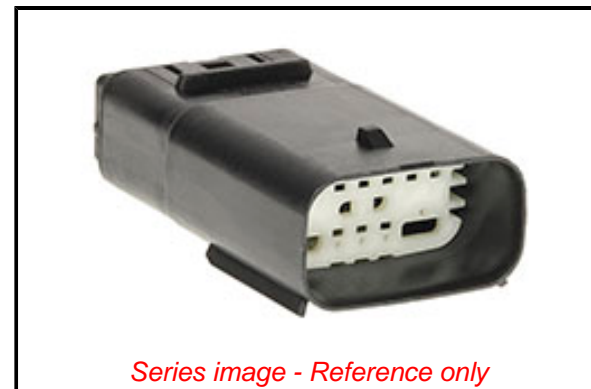

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[160112](#) Series

Mates With

MX150 Hybrid Sealed Female Connector Assembly [160111](#)

Use With

MX150 Male Terminal [33000](#) , [33011](#) ,
Industry Standard Terminal 2.80mm