

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2004850710](#)
Status: **Active**
Overview: [Easy-On FFC FPC Connectors](#)
Description: Easy-On FFC/FPC One-Touch Connector, 0.50mm Pitch, Vertical, 5.60mm Height, 105°C Operating Temperature, 10 Circuits, Gold (Au) Plating, with Ground Terminal

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification 2004851400-PS-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification 2004859200-SPK-201 \(PDF\)](#)

General

Product Family [FFC/FPC Connectors](#)
Series [200485](#)
Overview [Easy-On FFC FPC Connectors](#)
Product Name [Easy-On](#)
UPC [191130074662](#)

Physical

Actuator Type [One-Touch](#)
Circuits (Loaded) [10](#)
Circuits (maximum) [10](#)
Color - Resin [Black](#)
Contact Position [N/A](#)
Durability (mating cycles max) [20](#)
Mated Height [5.60mm](#)
Material - Metal [Copper Alloy](#)
Material - Plating Mating [Gold](#)
Material - Resin [Liquid Crystal Polymer](#)
Net Weight [358.386/mg](#)
Number of Rows [1](#)
Orientation [Vertical](#)
PCB Mounting [Surface Mount](#)
PCB Retention [Yes](#)
Packaging Type [Embossed Tape on Reel](#)
Pitch - Mating Interface [0.50mm](#)
Polarized to PCB [Yes](#)
Stackable [No](#)
Temperature Range - Operating [-40° to +105°C](#)
Wire/Cable Type [FFC/FPC](#)


Electrical

Current - Maximum per Contact [0.5A](#)
Voltage - Maximum [50V](#)

Material Info

Reference - Drawing Numbers

Packaging Specification [2004859200-SPK-201](#)
Product Specification [2004851400-PS-000](#)
Sales Drawing [2004850700-000, 2004851700-000](#)

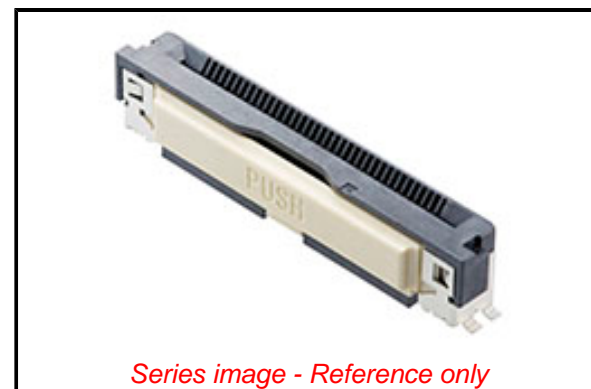

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[200485 Series](#)