



No.390, Yong He Road,
Shanghai 200072, China

TECHNICAL DATA SHEET CABLE ASSEMBLY

PART NUMBER :R284C0351066

Issue : NA

Date : NA


Customer :

Specification : NA

Issue : NA

Date : N/A

All dimensions are in mm

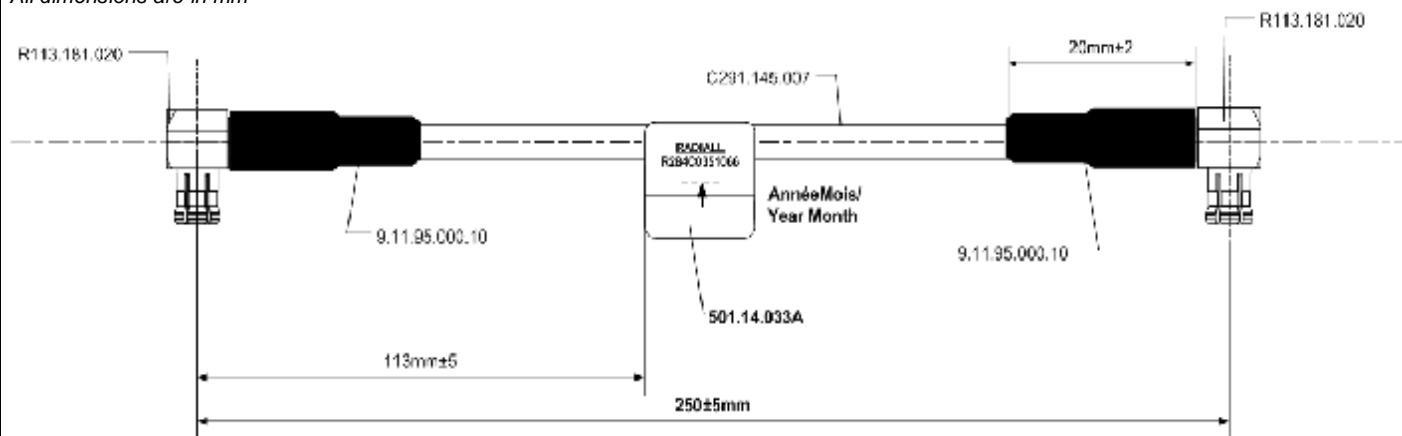

Connectors designation :

Connector 1 : MCX Right Angle Plug Crimp Type
Cable 2/50 S (R113.181.020)

Connector 2 : MCX Right Angle Plug Crimp Type
Cable 2/50 S (R113.181.020)

Cable designation :

Flexible Cable 2/50S (RG178)

Nominal length :

C291.145.007

Lg: 250 mm

Cable colour :

Brown

Outer diameter :

1.78 mm

Accessories :

HeatShrink Sleeves (9.11.95.000.10)

ELECTRICAL CHARACTERISTICS :

High Frequency

Characteristic impedance : 50 ± 2 Ohms

Frequency range : DC-3GHz

Insertion Loss : 0.87 dB max @ 3GHz & 20°C

VSWR. : TBT

Low Frequency

Insulation Resistance : 1000 MOhms min

Voltage Rating : 170 Veff max

MECHANICAL CHARACTERISTICS :

Recommend min. bend radius : 7 mm

Cable crush resistance : NA

Life (connectors) : 500 cycles

ENVIRONMENTAL CHARACTERISTICS :

Operating temperature range : -55° C to +155° C

Remark : NA

Attachment : R113.181.020-TDS,

C291.145.007 (RG178)-TDS

Cable Assembly is RoHS compliant.

CUSTOMER'S APPROVAL

Service or
Company's stamp

Name
Date

Peter	A	2007-5-25	Creation	Willy
Name	Issue	Date	Modification	Checked by