

DYMO®

LabelManager™ 210D




CREATE LABELS FAST WITH SMART KEYS

Customize labels using Computer-style keyboard and one-touch Smart Keys for fast formatting

Features

- Large LCD display
- Computer-style keyboard
- One-touch Smart Keys for fast formatting
- Long lasting rechargeable battery pack
- 20+ ways to format text
- 200+ symbols and clip-art images
- Print up to 1/2 in (12 mm) wide labels

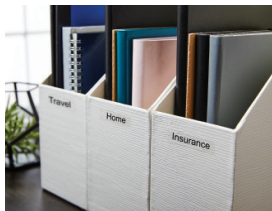

Single Unit Includes:

- LabelManager 210D
- D1 Starter Label Cassette, 12mm x 3m Black On White
- Quick Start Guide
- 2 + 1 - Year Limited Warranty*



Kit Includes:

- LabelManager 210D + Softcase Bag
- D1 Starter Label Cassette, 12mm x 3m Black On White
- Quick Start Guide
- Charging Adapter
- 2 + 1 - Year Limited Warranty*



Quick Specs	
Unit Dimensions (H x W x L)	155 x 165 x 64 mm
Weight (excluding battery)	435 g
Mac®/PC Compatible	No
Accepts Label Sizes	6mm, 9mm and 12mm
Tape Platform	D1, Durables
Resolution	180 dpi
Printing System	Thermal Transfer
Print Speed	12 mm/sec
Barcodes	No
Cutter Type	Manual
Batteries	6 AA (not included)
Adapter	Yes (optional, sold separately)
Networking	No
Country of Origin	China

Item Number	Description	Length (cm)	Width (cm)	Height (cm)	QTY	EAN	Customer Price
S0784440	LabelManager 210D QWERTY	9.7	22.2	20.3	1	3501170784440	
2094492	LabelManager 210D QWERTY KIT	6.4	16.5	15.5	1	3501170964071	
Accessories (www.dymo.com)							
S0721430	Charging Adapter	11.5	6.0	9.0	1	-	

* +1 year if registered on the Dymo website



100% recycled material used for external cassette



+40% of DYMO® labels are produced* using „Water based solvents“.




DYMO® high quality labels are made in Belgium



D1 Standard Polyester Labels

For hundreds of tasks around the office or home office, such as filing, storage and asset tracking.
Temperature rating: -18°C to 90°C


D1 STANDARD LABELS (7 m)	6 mm	9 mm	12 mm
ABC	S0720780	S0720680	S0720530
ABC	S0720770	S0720670	S0720500
ABC	S0720790	S0720730	S0720580
ABC	-	S0720710	S0720560
ABC	-	S0720740	S0720590
ABC	-	S0720720	S0720570
ABC	-	-	S0720610
ABC	-	S0720690	S0720540
ABC	-	-	S0720510
ABC	-	-	S0720600
ABC	-	S0720700	S0720550
ABC	-	-	S0720520
D1 STANDARD MULTIPACKS (7 m)	6 mm	9 mm	12 mm
ABC	-	2093096	2093097

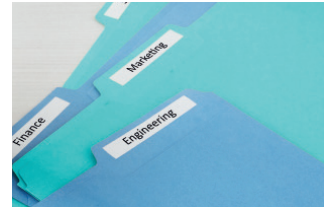

D1 Durable Vinyl Labels

Industrial strength adhesive helps to ensure labels stay stuck to a variety of surfaces.
Temperature rating: -40°C to 80°C

D1 DURABLE LABELS (3 m)	12 mm
ABC	1978366
ABC	1978365
ABC	1978367
D1 DURABLE LABELS (5.5 m)	12 mm
ABC	1978364

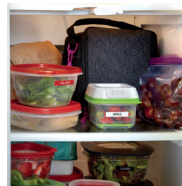

D1 Permanent Polyester Labels

Professional, polished finish ideal for panels, blocks, faceplates, shelves, bins and more.
Temperature rating: -40°C to 150°C*

D1 PERMANENT POLYESTER (5.5 m)	12 mm
ABC	S0718060

*depends on surface



D1 Flexible Nylon Labels

Specifically designed for curved surfaces and wire and cable marking.
Temperature rating: -40°C to 60°C

D1 FLEXIBLE NYLON (3.5 m)	12 mm
ABC	S0718040



The DYMO® high quality labels are made in Belgium



© 2021 Newell Brands

This information is being provided for general information purposes and the compliance standards and certifications referenced herein are based on current standards which are subject to change.

