


Part Number: 13211440

| Type         | Size | Rating     | Description               |
|--------------|------|------------|---------------------------|
| Incandescent | B-3½ | 7.2V 0.75A | Krypton Pre-Focus (torch) |

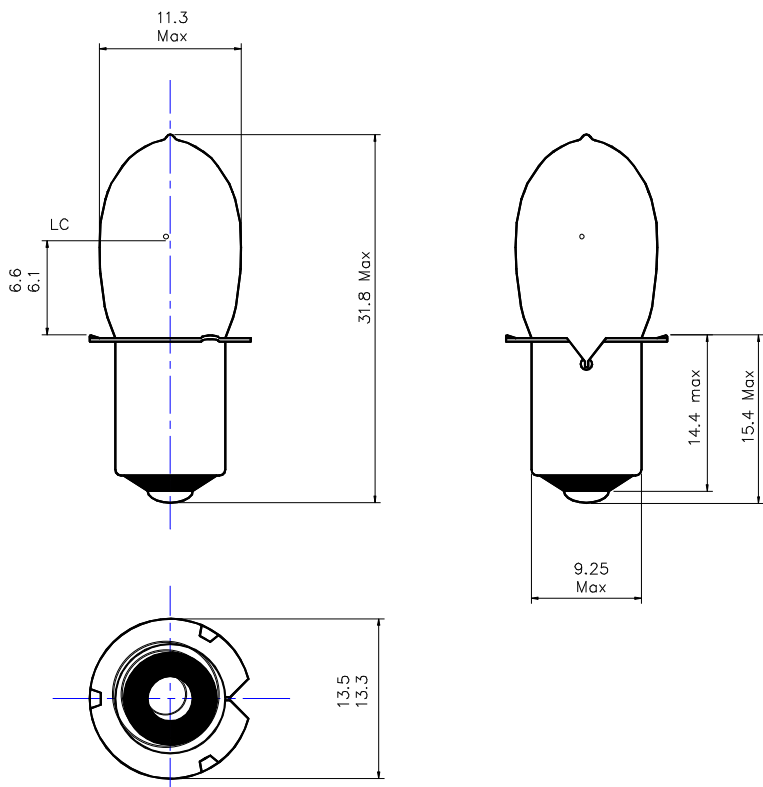

Dimensions in millimetre

| TEST VOLTS | CURRENT (mA) |      |      | LIGHT OUTPUT (Lm) |      |      | LIFE Hours |
|------------|--------------|------|------|-------------------|------|------|------------|
|            | Min.         | Nom. | Max. | Min.              | Nom. | Max. |            |
| 7.2        | 675          | 750  | 825  | 75                | 100  | 125  | 15         |

Notes:

- 1 **Base Type** P13.5s Nickel plated pre-focus
- 2 **Filament Shape** C-2R
- 3 **Lamp Marking** 7.2V 0.75A
- 4 **Environmental** RoHS & REACH SVHC compliant