


EvoSIGNAL / EvoSIGNAL Accessories
Midi Bracket WM GY

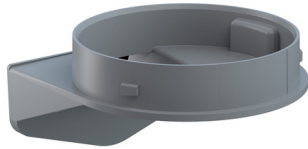


Part No.: 261.700.07



MECHANICAL DATA	
Length	90 mm
Width	85 mm
Height	53 mm
Materials	PC/ABS
Housing colour	Grey
Protection category	IP66
Cable entry	Through hole
Cable entry maximum	d = 9 mm
Type of fixing	Wall mounting
Working temperature minimum	-30°C
Working temperature maximum	+60°C
UL Type Rating	Type 12
Weight with packaging	54 g
Product weight	54 g

ELECTRICAL DATA	
Pollution degree	3

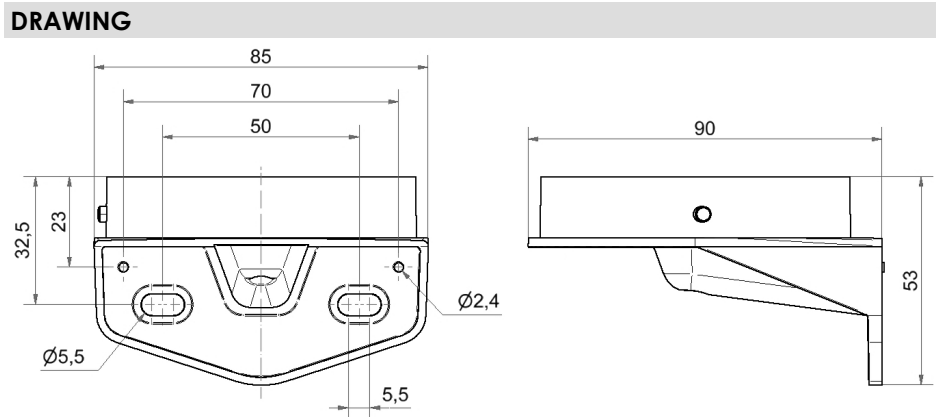

! For additional installation and mounting information, refer to the appropriate user guide at www.werma.com. This printed copy is for information only and is subject to alteration.