

# Hot Air Irons and Nozzles

## Hot Air Nozzles for 100 / 200 W Hot Air Stations



Order No.	Model	Description
005 27 118 99	HAP 1	<b>Hot air pencil set 100 W, 24 V</b> The HAP 1 provides a directional hot air flow that is adjustable. Electronic temperature control from 50°C to 550°C. Different nozzles available as accessory. Finger switch controls adjustable pump.
consists of:		
005 27 115 99	HAP 1	Hot air pencil 100 W, 24 V with hot air nozzle R 06 Ø 3,0 mm
005 15 152 99	WDH 30	Safety rest
005 87 278 21	R 04	Hot air nozzle Ø 1,2 mm




Order No.	Model	Description
005 27 117 99	HAP 200	<b>Hot air pencil set 200 W, 24 V</b> The HAP 200 provides a directional hot air flow that is adjustable. Electronic temperature control from 50°C to 550°C. Different nozzles available as accessory. Finger switch controls adjustable pump. For WR 3M only.
consists of:		
005 27 116 99	HAP 200	Hot air pencil 200 W, 24 V with hot air nozzle R 06 Ø 3,0 mm
005 15 152 99	WDH 30	Safety rest
005 87 278 21	R 04	Hot air nozzle Ø 1,2 mm



Order No.	Model	Description
005 15 155 99	WRK	<b>Desoldering system (see page 120)</b>

### Hot Air Nozzles for HAP 1 and HAP 200

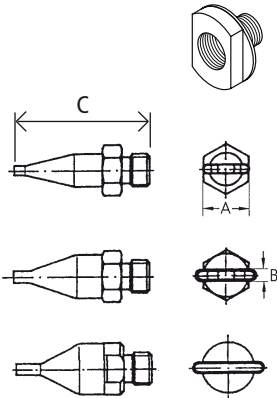

Order No.	Model	Description	Width A	Thickness B	Length C
005 87 617 28		Adapter M6 for HAP 200			
005 87 277 74	F02	Flat nozzle	8,0 mm	1,5 mm	
005 87 277 73	F04	Flat nozzle	10,5 mm	1,5 mm	
005 87 277 72	F06	Flat nozzle	12,0 mm	1,5 mm	