

PRODUCT DATASHEET

HQL LED 3600 lm 29 W/2700K E27

HQL LED PRO | LED replacement for HID lamps for outdoor application



AREAS OF APPLICATION

- Streets
- Area lighting
- Pedestrian zones
- Parks
- Outdoor applications only in suitable luminaires

PRODUCT BENEFITS

- Saves up to 78 % energy when used as replacement for mercury vapor lamps (HQL)
- Low maintenance costs thanks to long lifetime
- Instant 100 % light, no warm-up time

PRODUCT FEATURES

- Replacement for HQL: Suitable for operation with conventional control gear (CCG) for HQL or 230 V mains
- Replacement for other HID: Suitable for operation with line voltage without control gear
- Power factor: 0.9
- Type of protection: IP65
- High surge protection: up to 4 kV (L-N)



TECHNICAL DATA

Electrical data

Rated wattage	29.00 W
Nominal wattage	29.00 W
Nominal voltage	220...240 V
Max. lamp no. on circuit break. 10 A (B)	48
Max. lamp no. on circuit break. 16 A (B)	76
Operating frequency	50/60 Hz
Inrush current	10 A
Power factor λ	> 0.90


Photometrical data

Nominal luminous flux	3600 lm
Rated luminous flux	3600 lm
Lumen main.fact.at end of nom.life time	0.70
Light color (designation)	Warm White
Color temperature	2700 K
Luminous flux	3600 lm
Color rendering index Ra	≥ 80
Standard deviation of color matching	≤ 6 sdc _m
Rated color temperature	2700 K
Color rendering index Ra	≥ 80

Light technical data

Warm-up time (60 %)	< 0.50 s
Beam angle	360 °
Starting time	< 0.5 s

Dimensions & weight

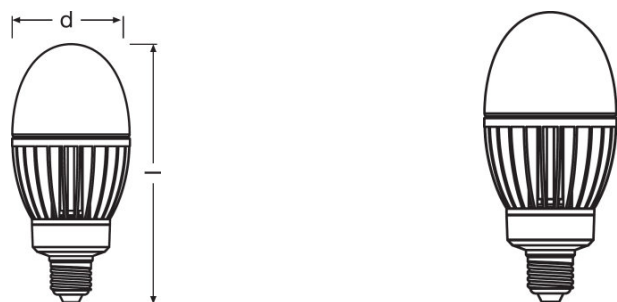

Overall length	168.0 mm
Diameter	76.0 mm
Outer bulb	-
Length	168.0 mm

Temperatures & operating conditions

Ambient temperature range	-20...+60 °C
Maximum temperature at tc test point	105 °C

Lifespan

Nominal lamp life time	50000 h
Rated lamp life time	50000 h
Number of switching cycles	100000
Lumen maintenance at end of service life	0.70

Additional product data

Base (standard designation)	E27
Mercury content	0.0 mg
Mercury-free	Yes
Design / version	frosted
Show WEEE picto	Yes

Capabilities

Dimmable	No
-----------------	----

Certificates & standards

Energy efficiency class	A+
Energy consumption	29 kWh/1000h

Country-specific categorizations

Order reference	HQLLED3600 29W/
------------------------	-----------------

SAFETY ADVICE

The bulb may be larger and heavier than the replaced bulb. Before installation it must be checked, if the luminaire and especially the holder is capable of carrying the weight of the lamp. If possible, please install the safety rope included in the package containing the lamp for the types 46 W and 95 W.

Not suitable for operation with ignitors

Operation on the capacitor can lead to a reduction of the power factor of the system.

When installed horizontally, the t_c point of the lamp is located on the top side of the lamp.

Use in tight luminaires and luminaires with tight reflectors not recommended.

LOGISTICAL DATA

Product code	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Gross weight	Volume
4058075453920	Folding carton box 1	107 mm x 107 mm x 203 mm	446.00 g	2.32 dm ³
4058075453937	Shipping carton box 6	335 mm x 230 mm x 220 mm	3347.00 g	16.95 dm ³

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.