

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0153660321](#)  
**Status:** **Active**  
**Overview:** FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers  
**Description:** 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Tin (Sn) Plating, 30 Circuits, with Shield

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification 153660001-000 \(PDF\)](#)

**General**

Product Family Cable  
 Series [15366](#)  
 Crimp Quality Equipment Yes  
 Overview [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)

Product Name Premo-Flex FFC Jumper  
 UPC 193264623396

**Physical**

Cable Length 102.00mm  
 Circuits (Loaded) 30  
 Contact Layout Type A (same side)  
 Material - Plating Mating Tin  
 Packaging Type Bag  
 Pitch - Mating Interface 0.50mm  
 Temperature Range - Operating -40° to +105°C  
 Wire Size AWG N/A  
 Wire/Cable Type Flat Flex Cable


**Electrical**

Current - Maximum per Contact 0.5A  
 Voltage - Maximum N/A

**Material Info**

**Reference - Drawing Numbers**

Product Specification 153660001-000  
 Sales Drawing 153660001-001

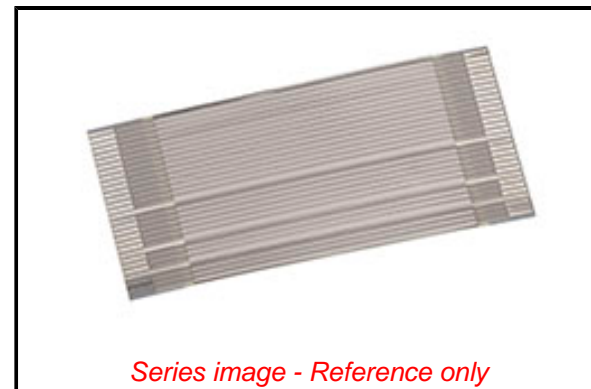

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 D(2020)9139-DC (19  
 Jan 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[15366](#) Series

**Mates With**

Easy-On FFC/FPC Connector [524353033](#)  
 , [541043033](#) , [524373033](#) , [541323033](#) ,  
[5019513 000](#) , [525593033](#)