

Han 300A crimp module, male

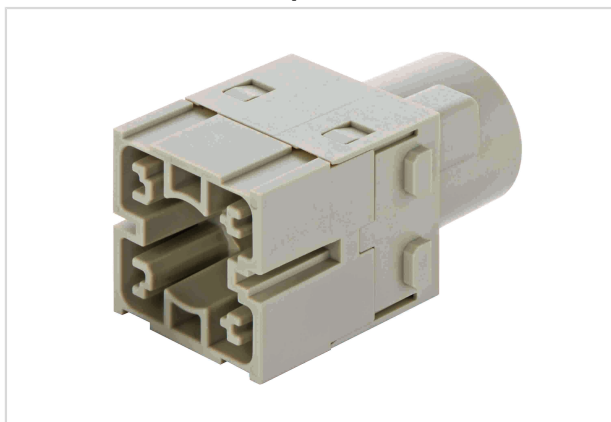


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 001 3004
Specification	Han 300A crimp module, male
HARTING eCatalogue	https://b2b.harting.com/09140013004

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® 300 A module

Version

Termination method	Crimp termination Axial screw termination
Gender	Male
Number of contacts	1
Details	Please order contacts separately.

Technical characteristics

Conductor cross-section	95 ... 120 mm ²
Rated current	300 A
Rated voltage	1,000 V
Rated voltage	1,000 V AC 1,300 V DC
Rated impulse voltage	8 kV
Pollution degree	3
Insulation resistance	>10 ¹⁰ Ω
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500



Pushing Performance

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0

Specifications and approvals

Specifications	EN 50124-1
	EN 60664-1
	IEC 61984

Commercial data

Packaging size	1
Net weight	25 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27440217 Module for industrial connectors (power/signals)