

## Han 200A crimp module, male

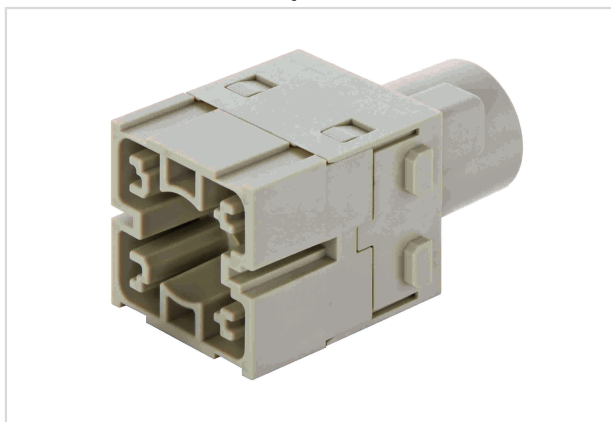


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 001 3003
Specification	Han 200A crimp module, male
HARTING eCatalogue	<a href="https://b2b.harting.com/09140013003">https://b2b.harting.com/09140013003</a>

### Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® 200 A module

### Version

Termination method	Crimp termination
Gender	Male
Number of contacts	1
Details	Please order crimp contacts separately.

### Technical characteristics

Conductor cross-section	16 ... 70 mm <sup>2</sup>
Rated current	200 A
Rated voltage	1,000 V
Rated voltage	1,000 V AC 1,300 V DC
Rated impulse voltage	8 kV
Pollution degree	3
Insulation resistance	>10 <sup>10</sup> Ω
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500



Pushing Performance

## Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0

## Specifications and approvals

Specifications	EN 50124-1
	EN 60664-1
	IEC 61984
Approvals	DNV GL

## Commercial data

Packaging size	1
Net weight	0.025 kg
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27440217 Module for industrial connectors (power/signals)