



TECHNICAL DATA SHEET

Part#: M-3-CO-ET


Tweezers - Straight Very Fine Point - Miniature - Cobalt - Ergo

The M-3-CO-ET five star Cobaltima[®] miniature straight very fine pointed tweezer with tips .003" wide x .0016" high is made of a cobalt alloy, which is extremely hard, temperature resistant to 932°F and corrosion resistant. This tool includes an ergonomic handle. The body is .04" in thickness for light pressure use. The tips are radius which eliminates marring and scratching of delicate parts and wires. It features our Ergo-Tweezer[®] soft cushioned Anti-Static grips (10^{10} ohms/sq surface resistivity), which also protect the user from heat.

- Precision Level ★★★★★
- Material Cobalt
- Surface Resistivity 10^{10} ohms/sq
- Shape Straight
- Group
- Weight (OZ) 1
- Tip Size (CTM) .003" (.08mm) x .0016" (.04mm)
- Tip Angle Straight
- Tip Length n/a
- Body Width 0.27" (6.75mm)
- Body Height One Leg .0394" (1mm)
- OAL 3.13" (78.25mm)
- Country of Origin Switzerland
- UPC 662847014475
- Schedule B 8203.20.20.00
- Harmonization Code 8203.20.20
- ECCN EAR99
- UNSPSC Code 27112105



C.T.M.
Critical Tip Measurements
(Tip Width and Thickness of one point)

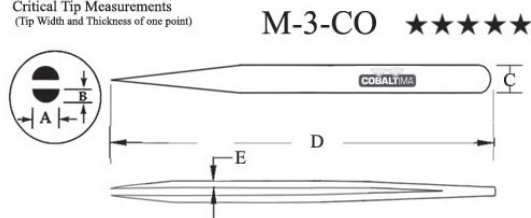

EXCELTA[®]
CORPORATION

- A) 0.003"
- B) 0.0016"
- C) 0.270"
- D) 3.125"
- E) 0.040"