

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2152793603](#)
Status: **Active**
Overview: Temperature Sensor Cable Assemblies
Description: Epoxy Coated NTC Thermistor Cables, 25.00mm Length, 4035 Beta Value, 10k# Resistance at 25°C with 1% Tolerance, Black

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|----------------------------|---|
| Product Family | Cable Assemblies |
| Series | 215279 |
| Application | Temperature Sensing |
| Assembly Configuration | Single Ended Connector |
| Beta Value (K) | 4035 |
| Connector to Connector | NTC Thermistor-to-Pigtail |
| Overview | Temperature Sensor Cable Assemblies |
| Product Name | NTC Temperature Sensor |
| Resistance Tolerance (%) | 1 |
| Resistance at 25°C (kohms) | 10 |
| UPC | 195842044548 |


Physical

| | |
|---------------------|---------|
| Cable Length | 25.00mm |
| Circuits (Loaded) | 1 |
| Color - Resin | Black |
| Gender | N/A |
| Lock to Mating Part | Yes |
| Net Weight | 0.110/g |
| Packaging Type | Bag |
| Single Ended | Yes |
| Wire Size AWG | 28 |
| Wire/Cable Type | N/A |

Material Info

Reference - Drawing Numbers

| | |
|---------------|----------------|
| Sales Drawing | 2152793603-000 |
|---------------|----------------|

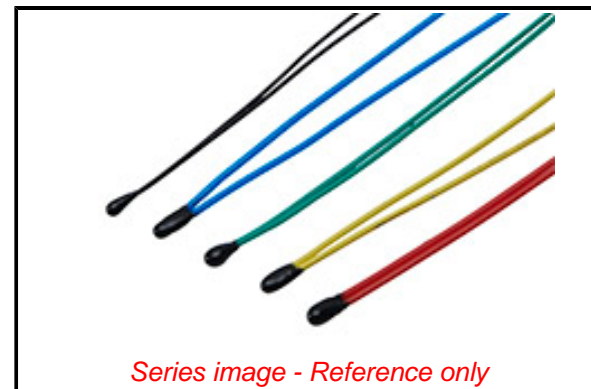

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 15(a)

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)

Lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[215279 Series](#)