

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2177961043](#)  
**Status:** **Active**  
**Overview:** [Off-the-Shelf Cable Assemblies](#)  
**Description:** KK 254-to-KK 254 Off-the-Shelf (OTS) Cable Assembly, 2.54mm Pitch, Single Row, 600.00mm Length, 4 Circuits, Natural

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<a href="#">217796</a>
Assembly Configuration	Dual Ended Connectors
Connector to Connector	KK 254-to-KK 254
Overview	<a href="#">Off-the-Shelf Cable Assemblies</a>
Product Name	KK 254
Type	Discrete Wire Assembly
UPC	195842122857


**Physical**

Cable Length	600.00mm
Circuits (Loaded)	4
Color - Resin	Natural (White)
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	11.532/g
Number of Rows	1
Pitch - Mating Interface	2.54mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.57mm max.
Wire Size AWG	22
Wire/Cable Type	UL 11028

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	2177961041-000
---------------	----------------

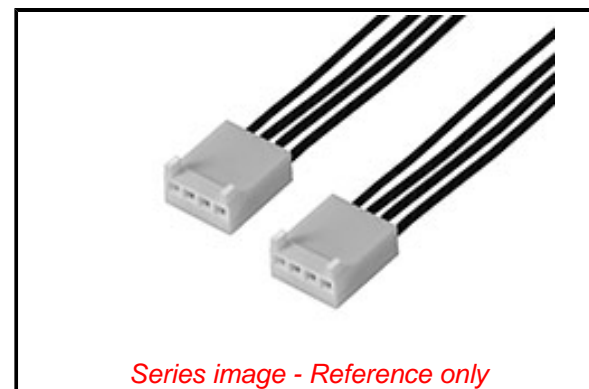

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2020)9139-DC (19  
Jan 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[217796](#) Series

**Mates With**

KK254 PCB Headers<br>[42375](#) , [42377](#)  
, [42376](#) , [4030](#) , [6373](#) , [6410](#) , [1718](#) 56,  
[171857](#)

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**