



Data sheet | Item number: 2250-1207

2-conductor miniature ground terminal block; with push-button; 1 mm<sup>2</sup>; side and center marking; for DIN-15 rail; Push-in CAGE CLAMP®; 1,00 mm<sup>2</sup>; green-yellow

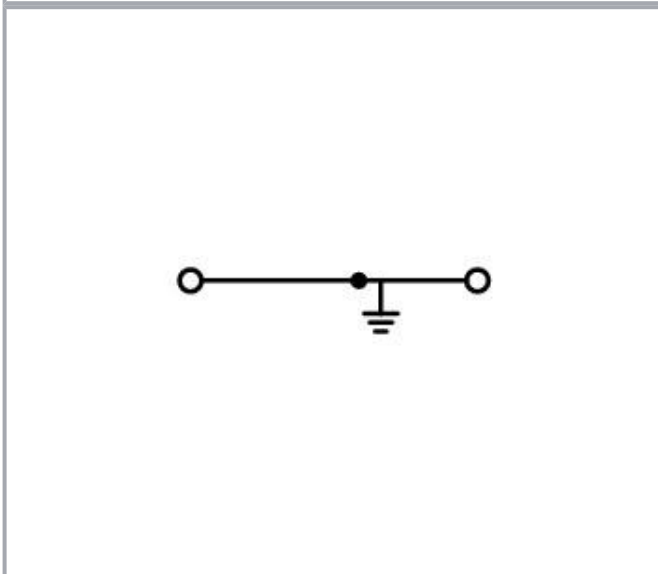

[www.wago.com/2250-1207](http://www.wago.com/2250-1207)

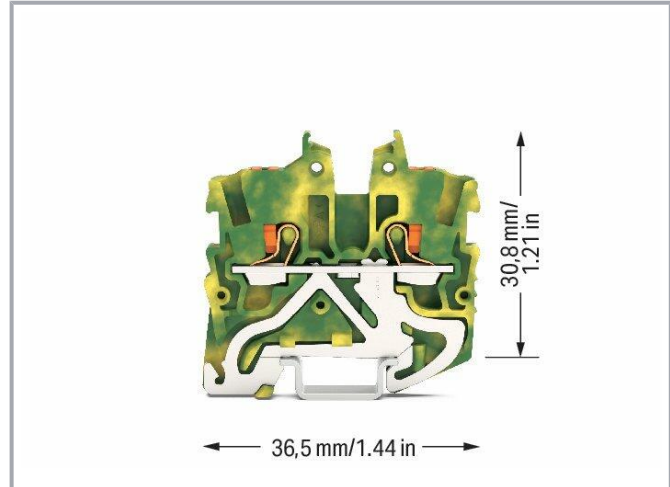

Subject to changes. Please also observe the further product documentation!

WAGO Kontakttechnik GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at 01788 568 008.



## Data

### Electrical data

#### Ratings per IEC/EN

|             |                  |
|-------------|------------------|
| Ratings per | IEC/EN 60947-7-2 |
|-------------|------------------|

#### Connection data

|  |   |
|--|---|
| Connection technology                                      | Push-in CAGE CLAMP®   |
| Actuation type   | Push-in<br>Push-button<br>Operating tool  |
| Connectable conductor materials                            | Copper<br>Copper  |
| Nominal cross-section                                      | 1 mm <sup>2</sup>   |
| Solid conductor  | 0.14 ... 1.5 mm <sup>2</sup> / 24 ... 16 AWG  |
| Solid conductor; push-in termination                       | 0.5 ... 1.5 mm <sup>2</sup> / 20 ... 16 AWG   |
| Fine-stranded conductor                                    | 0.14 ... 1.5 mm <sup>2</sup> / 24 ... 16 AWG  |
| Fine-stranded conductor; with insulated ferrule            | 0.14 ... 0.75 mm <sup>2</sup> / 24 ... 18 AWG   |
| Fine-stranded conductor; with ferrule; push-in termination | 0.5 ... 0.75 mm <sup>2</sup> / 20 ... 18 AWG  |
| Note (conductor cross-section)                             | Depending on the conductor characteristic, a conductor with a smaller cross-section can also be inserted via push-in termination. |
| Strip length   | 9 ... 11 mm / 0.35 ... 0.43 inch  |
| Total number of connection points                          | 2   |
| Total number of potentials                                 | 1   |
| Number of levels   | 1   |
| Wiring direction   | Front-entry wiring  |
| Number of jumper slots                                     | 1   |

#### Physical data

|                                   |                     |
|-----------------------------------|---------------------|
| Width                             | 3.5 mm / 0.138 inch |
| Height                            | 34 mm / 1.339 inch  |
| Depth from upper edge of DIN-rail | 28 mm / 1.102 inch  |

#### Mechanical data

|               |                     |
|---------------|---------------------|
| Design        | horizontal type     |
| Mounting type | DIN-15 rail         |
| Marking level | Center/side marking |

Subject to changes. Please also observe the further product documentation!

WAGO Kontakttechnik GmbH & Co. KG  
 Hansastr. 27  
 32423 Minden  
 Phone: +49571 887-0 | Fax: +49571 887-169  
 Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
 We are always happy to take your call at 01788 568 008.

## Material data





|                             |                  |
|-----------------------------|------------------|
| Color                       | green-yellow     |
| Insulation material         | Polyamide (PA66) |
| Flammability class per UL94 | V0               |
| Weight                      | 3.8g             |

## Commercial data


|                       |               |
|-----------------------|---------------|
| Packaging type        | BOX           |
| Country of origin     | DE            |
| GTIN                  | 4055143981729 |
| Customs tariff number | 85369010000   |

## Approvals / Certificates

### Ex-Approvals

| Logo   | Approval                                       | Additional Approval Text | Certificate name  |
|--|--|--------------------------|---|
|   | AEx<br>Underwriters Laboratories Inc.          | UL 60079                 | E185892   |
|  | ATEX<br>Physikalisch Technische Bundesanstalt  | EN IEC 60079-0           | PTB 19 ATEX 1019<br>U (II 2G Ex eb IIC Gb<br>or I M 2 EX eb I Mb) |
|  | CCCEX<br>CQST/CNEx                             | CNCA-C23-01              | 2020312313000289  |
|  | IECEX<br>Physikalisch Technische Bundesanstalt | IEC 60079                | IECEX PTB 19.0050<br>U (Ex eb IIC Gb or<br>EX eb I Mb)            |

### Country specific Approvals

| Logo   | Approval                        | Additional Approval Text | Certificate name |
|--|---------------------------------|--------------------------|------------------|
|  | CCA<br>DEKRA Certification B.V. | EN 60947                 | NTR NL<br>7839   |
|  | CCA                             | EN 60998                 | NTR NL           |

Subject to changes. Please also observe the further product documentation!



DEKRA Certification B.V.

7840

CSA  
CSA

C22.2 No. 158

80034182

KEMA/KEUR  
DEKRA Certification B.V.


EN 60947

71-  
113930KEMA/KEUR  
DEKRA Certification B.V.

EN 60998

71-  
113957

## UL-Approvals

| Logo  | Approval                                | Additional Approval Text | Certificate name    |
|---|---|--------------------------|---------------------|
|  | cURus<br>Underwriters Laboratories Inc. | UL 1059                  | E45172-<br>20200212 |




## Required accessories

## End plate

|   |   |  |
|---|---|--|
|  | Item no.: 2050-1291<br>End and intermediate plate; 1.1 mm thick; gray | <a href="http://www.wago.com/2050-1291">www.wago.com/2050-1291</a> |
|---|---|--|

## Optional accessories


 


 


 



 



## Jumpers

|  |  |  |
|--|--|--|
|  | Item no.: 2000-402<br>Jumper; 2-way; insulated; light gray   | <a href="http://www.wago.com/2000-402">www.wago.com/2000-402</a>                 |
|  | Item no.: 2000-402/000-005<br>Jumper; 2-way; insulated; red  | <a href="http://www.wago.com/2000-402/000-005">www.wago.com/2000-402/000-005</a> |
|  | Item no.: 2000-402/000-006<br>Jumper; 2-way; insulated; blue | <a href="http://www.wago.com/2000-402/000-006">www.wago.com/2000-402/000-006</a> |

Subject to changes. Please also observe the further product documentation!

WAGO Kontakttechnik GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)








Do you have any questions about our products?  
We are always happy to take your call at 01788 568 008.

|  |  |  |
|--|--|--|
|    | <b>Item no.: 2000-402/000-018</b><br>Jumper; 2-way; insulated; yellow-green          | <a href="http://www.wago.com/2000-402/000-018">www.wago.com/2000-402/000-018</a> |
|    | <b>Item no.: 2000-403</b><br>Jumper; 3-way; insulated; light gray                    | <a href="http://www.wago.com/2000-403">www.wago.com/2000-403</a>                 |
|    | <b>Item no.: 2000-403/000-005</b><br>Jumper; 3-way; insulated; red                   | <a href="http://www.wago.com/2000-403/000-005">www.wago.com/2000-403/000-005</a> |
|    | <b>Item no.: 2000-403/000-006</b><br>Jumper; 3-way; insulated; blue                  | <a href="http://www.wago.com/2000-403/000-006">www.wago.com/2000-403/000-006</a> |
|    | <b>Item no.: 2000-404</b><br>Jumper; 4-way; insulated; light gray                    | <a href="http://www.wago.com/2000-404">www.wago.com/2000-404</a>                 |
|    | <b>Item no.: 2000-404/000-005</b><br>Jumper; 4-way; insulated; red                   | <a href="http://www.wago.com/2000-404/000-005">www.wago.com/2000-404/000-005</a> |
|    | <b>Item no.: 2000-404/000-006</b><br>Jumper; 4-way; insulated; blue                  | <a href="http://www.wago.com/2000-404/000-006">www.wago.com/2000-404/000-006</a> |
|   | <b>Item no.: 2000-405</b><br>Jumper; 5-way; insulated; light gray                    | <a href="http://www.wago.com/2000-405">www.wago.com/2000-405</a>                 |
|  | <b>Item no.: 2000-405/000-005</b><br>Jumper; 5-way; insulated; red                   | <a href="http://www.wago.com/2000-405/000-005">www.wago.com/2000-405/000-005</a> |
|  | <b>Item no.: 2000-405/000-006</b><br>Jumper; 5-way; insulated; blue                  | <a href="http://www.wago.com/2000-405/000-006">www.wago.com/2000-405/000-006</a> |
|  | <b>Item no.: 2000-405/011-000</b><br>Star point jumper; 3-way; insulated; light gray | <a href="http://www.wago.com/2000-405/011-000">www.wago.com/2000-405/011-000</a> |
|  | <b>Item no.: 2000-406</b><br>Jumper; 6-way; insulated; light gray                    | <a href="http://www.wago.com/2000-406">www.wago.com/2000-406</a>                 |
|  | <b>Item no.: 2000-406/000-005</b><br>Jumper; 6-way; insulated; red                   | <a href="http://www.wago.com/2000-406/000-005">www.wago.com/2000-406/000-005</a> |
|  | <b>Item no.: 2000-406/000-006</b><br>Jumper; 6-way; insulated; blue                  | <a href="http://www.wago.com/2000-406/000-006">www.wago.com/2000-406/000-006</a> |
|  | <b>Item no.: 2000-406/020-000</b><br>Delta jumper; insulated; light gray             | <a href="http://www.wago.com/2000-406/020-000">www.wago.com/2000-406/020-000</a> |
















Subject to changes. Please also observe the further product documentation!

|  |  |  |
|--|--|--|
|    | <b>Item no.: 2000-407</b><br>Jumper; 7-way; insulated; light gray        | <a href="http://www.wago.com/2000-407">www.wago.com/2000-407</a>                 |
|     | <b>Item no.: 2000-407/000-005</b><br>Jumper; 7-way; insulated; red       | <a href="http://www.wago.com/2000-407/000-005">www.wago.com/2000-407/000-005</a> |
|     | <b>Item no.: 2000-407/000-006</b><br>Jumper; 7-way; insulated; blue      | <a href="http://www.wago.com/2000-407/000-006">www.wago.com/2000-407/000-006</a> |
|    | <b>Item no.: 2000-408</b><br>Jumper; 8-way; insulated; light gray        | <a href="http://www.wago.com/2000-408">www.wago.com/2000-408</a>                 |
|     | <b>Item no.: 2000-408/000-005</b><br>Jumper; 8-way; insulated; red       | <a href="http://www.wago.com/2000-408/000-005">www.wago.com/2000-408/000-005</a> |
|     | <b>Item no.: 2000-408/000-006</b><br>Jumper; 8-way; insulated; blue      | <a href="http://www.wago.com/2000-408/000-006">www.wago.com/2000-408/000-006</a> |
|    | <b>Item no.: 2000-409</b><br>Jumper; 9-way; insulated; light gray        | <a href="http://www.wago.com/2000-409">www.wago.com/2000-409</a>                 |
|   | <b>Item no.: 2000-409/000-005</b><br>Jumper; 9-way; insulated; red       | <a href="http://www.wago.com/2000-409/000-005">www.wago.com/2000-409/000-005</a> |
|   | <b>Item no.: 2000-409/000-006</b><br>Jumper; 9-way; insulated; blue      | <a href="http://www.wago.com/2000-409/000-006">www.wago.com/2000-409/000-006</a> |
|  | <b>Item no.: 2000-410</b><br>Jumper; 10-way; insulated; light gray       | <a href="http://www.wago.com/2000-410">www.wago.com/2000-410</a>                 |
|   | <b>Item no.: 2000-410/000-005</b><br>Jumper; 10-way; insulated; red      | <a href="http://www.wago.com/2000-410/000-005">www.wago.com/2000-410/000-005</a> |
|   | <b>Item no.: 2000-410/000-006</b><br>Jumper; 10-way; insulated; blue     | <a href="http://www.wago.com/2000-410/000-006">www.wago.com/2000-410/000-006</a> |
|  | <b>Item no.: 2000-433</b><br>Jumper; from 1 to 3; insulated; light gray  | <a href="http://www.wago.com/2000-433">www.wago.com/2000-433</a>                 |
|  | <b>Item no.: 2000-433/000-005</b><br>Jumper; from 1 to 3; insulated; red | <a href="http://www.wago.com/2000-433/000-005">www.wago.com/2000-433/000-005</a> |

Subject to changes. Please also observe the further product documentation!









|   |  |  |
|---|--|--|
|   | <b>Item no.: 2000-433/000-006</b><br>Jumper; from 1 to 3; insulated; blue  | <a href="http://www.wago.com/2000-433/000-006">www.wago.com/2000-433/000-006</a> |
|   | <b>Item no.: 2000-434</b><br>Jumper; from 1 to 4; insulated; light gray  | <a href="http://www.wago.com/2000-434">www.wago.com/2000-434</a>                 |
|   | <b>Item no.: 2000-435</b><br>Jumper; from 1 to 5; insulated; light gray  | <a href="http://www.wago.com/2000-435">www.wago.com/2000-435</a>                 |
|   | <b>Item no.: 2000-436</b><br>Jumper; from 1 to 6; insulated; light gray  | <a href="http://www.wago.com/2000-436">www.wago.com/2000-436</a>                 |
|   | <b>Item no.: 2000-437</b><br>Jumper; from 1 to 7; insulated; light gray  | <a href="http://www.wago.com/2000-437">www.wago.com/2000-437</a>                 |
|   | <b>Item no.: 2000-438</b><br>Jumper; from 1 to 8; insulated; light gray  | <a href="http://www.wago.com/2000-438">www.wago.com/2000-438</a>                 |
|   | <b>Item no.: 2000-439</b><br>Jumper; from 1 to 9; insulated; light gray  | <a href="http://www.wago.com/2000-439">www.wago.com/2000-439</a>                 |
|   | <b>Item no.: 2000-440</b><br>Jumper; from 1 to 10; insulated; light gray   | <a href="http://www.wago.com/2000-440">www.wago.com/2000-440</a>                 |
|    | <b>Item no.: 210-103</b><br>Wire commoning chain; insulated; black   | <a href="http://www.wago.com/210-103">www.wago.com/210-103</a>                   |
|  | <b>Item no.: 210-123</b><br>Wire commoning chain; insulated; blue  | <a href="http://www.wago.com/210-123">www.wago.com/210-123</a>                   |
| <b>Marking accessories</b>  |  |  |
|  | <b>Item no.: 2009-110</b><br>Marking strips; for Smart Printer; on reel; not stretchable; plain; snap-on type; white | <a href="http://www.wago.com/2009-110">www.wago.com/2009-110</a>                 |
|  | <b>Item no.: 2009-113</b><br>WMB-Inline; for Smart Printer; 2300 pieces on roll; plain; snap-on type; white          | <a href="http://www.wago.com/2009-113">www.wago.com/2009-113</a>                 |
|  | <b>Item no.: 2009-113/000-002</b><br>WMB-Inline; for Smart Printer; 2300 pieces on roll; plain; snap-on type; yellow | <a href="http://www.wago.com/2009-113/000-002">www.wago.com/2009-113/000-002</a> |
|  | <b>Item no.: 2009-113/000-005</b><br>WMB-Inline; for Smart Printer; 2300 pieces on roll; plain; snap-on type; red    | <a href="http://www.wago.com/2009-113/000-005">www.wago.com/2009-113/000-005</a> |
|  | <b>Item no.: 2009-113/000-006</b><br>WMB-Inline; for Smart Printer; 2300 pieces on roll; plain; snap-on type; blue   | <a href="http://www.wago.com/2009-113/000-006">www.wago.com/2009-113/000-006</a> |
|  | <b>Item no.: 2009-113/000-007</b><br>WMB-Inline; for Smart Printer; 2300 pieces on roll; plain; snap-on type; gray   | <a href="http://www.wago.com/2009-113/000-007">www.wago.com/2009-113/000-007</a> |

Subject to changes. Please also observe the further product documentation!

|  |  |  |
|--|--|--|
|     | <b>Item no.: 2009-113/000-012</b><br>WMB-Inline; for Smart Printer; 2300 pieces on roll; plain; snap-on type; orange   | <a href="http://www.wago.com/2009-113/000-012">www.wago.com/2009-113/000-012</a> |
|     | <b>Item no.: 2009-113/000-017</b><br>WMB-Inline; for Smart Printer; 2300 pieces on roll; plain; snap-on type; light green  | <a href="http://www.wago.com/2009-113/000-017">www.wago.com/2009-113/000-017</a> |
|     | <b>Item no.: 2009-113/000-023</b><br>WMB-Inline; for Smart Printer; 2300 pieces on roll; plain; snap-on type; green  | <a href="http://www.wago.com/2009-113/000-023">www.wago.com/2009-113/000-023</a> |
|     | <b>Item no.: 2009-113/000-024</b><br>WMB-Inline; for Smart Printer; 2300 pieces on roll; plain; snap-on type; violet   | <a href="http://www.wago.com/2009-113/000-024">www.wago.com/2009-113/000-024</a> |
|    | <b>Item no.: 2009-191</b><br>Group marker carrier  | <a href="http://www.wago.com/2009-191">www.wago.com/2009-191</a>                 |
|     | <b>Item no.: 793-3501</b><br>WMB marking card; as card; plain; snap-on type; white   | <a href="http://www.wago.com/793-3501">www.wago.com/793-3501</a>                 |
| <b>Push-in type wire jumper</b>  |  |  |
|     | <b>Item no.: 2009-402</b><br>Push-in type wire jumper; 0.75 mm <sup>2</sup> ; insulated; 60 mm long; gray  | <a href="http://www.wago.com/2009-402">www.wago.com/2009-402</a>                 |
|   | <b>Item no.: 2009-404</b><br>Push-in type wire jumper; 0.75 mm <sup>2</sup> ; insulated; 110 mm long; gray   | <a href="http://www.wago.com/2009-404">www.wago.com/2009-404</a>                 |
|   | <b>Item no.: 2009-406</b><br>Push-in type wire jumper; 0.75 mm <sup>2</sup> ; insulated; 250 mm long; gray   | <a href="http://www.wago.com/2009-406">www.wago.com/2009-406</a>                 |
| <b>Testing and measuring</b>   |  |  |
|   | <b>Item no.: 2009-174</b><br>Test plug adapter; for 4 mm Ø test plugs; for testing TOPJOB®S rail-mounted terminal blocks; gray   | <a href="http://www.wago.com/2009-174">www.wago.com/2009-174</a>                 |
|   | <b>Item no.: 2009-182</b><br>Testing tap; for max. 2.5 mm <sup>2</sup> ; tool-free connection for individual test wires 0.08 - 2.5 mm; gray  | <a href="http://www.wago.com/2009-182">www.wago.com/2009-182</a>                 |
|   | <b>Item no.: 210-136</b><br>Test plug; 2 mm Ø; with 500 mm cable; red  | <a href="http://www.wago.com/210-136">www.wago.com/210-136</a>                   |
|   | <b>Item no.: 210-137</b><br>Test plug; 2.3 mm Ø; with 500 mm cable; yellow   | <a href="http://www.wago.com/210-137">www.wago.com/210-137</a>                   |
| <b>Mounting</b>  |  |  |
|  | <b>Item no.: 249-101</b><br>Screwless end stop; 6 mm wide; for WMB markers; gray   | <a href="http://www.wago.com/249-101">www.wago.com/249-101</a>                   |
| <b>Ferrule</b>   |  |  |
|   | <b>Item no.: 216-241</b><br>Ferrule; Sleeve for 0.5 mm <sup>2</sup> / 20 AWG; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; white | <a href="http://www.wago.com/216-241">www.wago.com/216-241</a>                   |

Subject to changes. Please also observe the further product documentation!



|  |  |  |
|--|--|--|
|   | <b>Item no.: 216-242</b><br>Ferrule; Sleeve for 0.75 mm <sup>2</sup> / 18 AWG; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; gray | <a href="http://www.wago.com/216-242">www.wago.com/216-242</a> |
|   | <b>Item no.: 216-243</b><br>Ferrule; Sleeve for 1 mm <sup>2</sup> / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; red     | <a href="http://www.wago.com/216-243">www.wago.com/216-243</a> |
| <b>Carrier rail</b>  |  |  |
|   | <b>Item no.: 210-111</b><br>Steel carrier rail; 15 x 5.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; silver-colored  | <a href="http://www.wago.com/210-111">www.wago.com/210-111</a> |
|   | <b>Item no.: 210-295</b><br>Steel carrier rail; 15 x 5.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715; silver-colored  | <a href="http://www.wago.com/210-295">www.wago.com/210-295</a> |
|   | <b>Item no.: 210-296</b><br>Aluminum carrier rail; 15 x 5.5 mm; 1 mm thick; 2 m long; unslotted; similar to EN 60715; silver-colored   | <a href="http://www.wago.com/210-296">www.wago.com/210-296</a> |
| <b>Tool</b>  |  |  |
|  | <b>Item no.: 210-647</b><br>Operating tool; Blade: 2.5 x 0.4 mm; with a partially insulated shaft; multicoloured   | <a href="http://www.wago.com/210-647">www.wago.com/210-647</a> |
|  | <b>Item no.: 210-648</b><br>Operating tool; Blade: 2.5 x 0.4 mm; with a partially insulated shaft; angled; short   | <a href="http://www.wago.com/210-648">www.wago.com/210-648</a> |
|  | <b>Item no.: 210-719</b><br>Operating tool; Blade: 2.5 x 0.4 mm; with a partially insulated shaft  | <a href="http://www.wago.com/210-719">www.wago.com/210-719</a> |

## Downloads

### Documentation

#### Additional Information

|                        |            |               |          |
|------------------------|------------|---------------|----------|
| Technical explanations | 3 Apr 2019 | pdf<br>2.2 MB | Download |
|------------------------|------------|---------------|----------|

## CAD/CAE-Data

### CAD data

|                        |     |          |
|------------------------|-----|----------|
| 2D/3D Models 2250-1207 | URL | Download |
|------------------------|-----|----------|

### CAE data

|                        |     |          |
|------------------------|-----|----------|
| ZUKEN Portal 2250-1207 | URL | Download |
|------------------------|-----|----------|

|                             |     |          |
|-----------------------------|-----|----------|
| EPLAN Data Portal 2250-1207 | URL | Download |
|-----------------------------|-----|----------|

|  |     |          |
|--|-----|----------|
|  | URL | Download |
|--|-----|----------|

Subject to changes. Please also observe the further product documentation!

## Environmental Product Compliance

### Compliance Search


Environmental Product Compliance 2250-1207

[URL](#)

[Download](#)

2-conductor miniature ground terminal block; with push-button; 1 mm<sup>2</sup>; side and center marking; for DIN-15 rail; Push-in CAGE CLAMP®; 1,00 mm<sup>2</sup>; green-yellow

## Installation Notes

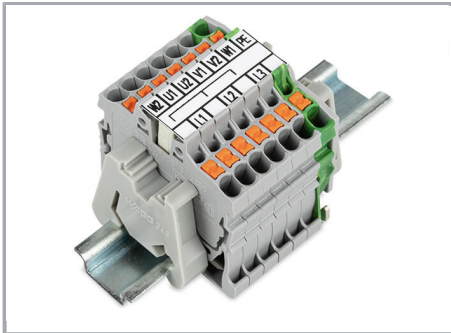

### Conductor termination



Insert solid conductors via push-in termination.




Insert ferruled conductors via push-in termination.




Insert fine-stranded conductors via operating tool.

Subject to changes. Please also observe the further product documentation!

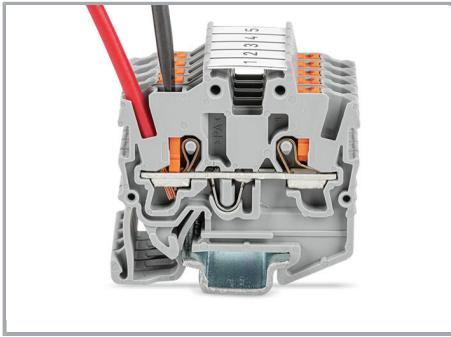


Remove all conductors via operating tool.


### Commoning

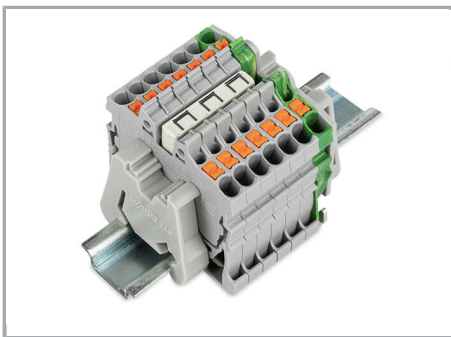


Insert a jumper (delta jumper) and push down until it hits the backstop (picture shows terminal blocks with push-buttons).

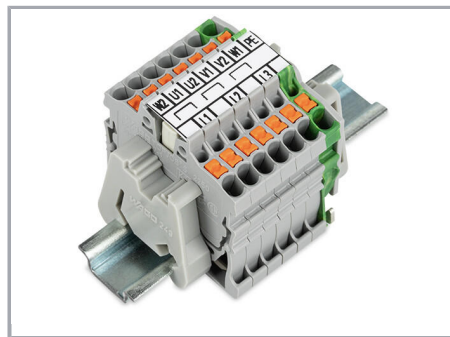

Marking strip (2009-110) inserted in the marking slot with jumper symbols of the inserted jumper (picture shows terminal blocks with push-buttons)

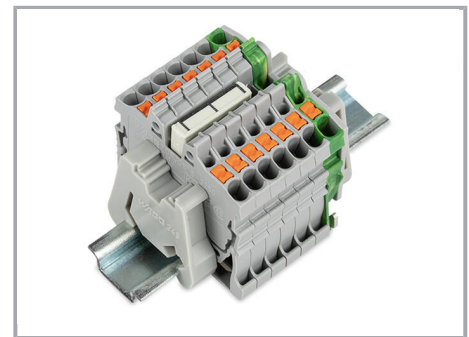


Insert a jumper (star point jumper) and push down until it hits the backstop (picture shows terminal blocks with push-buttons).

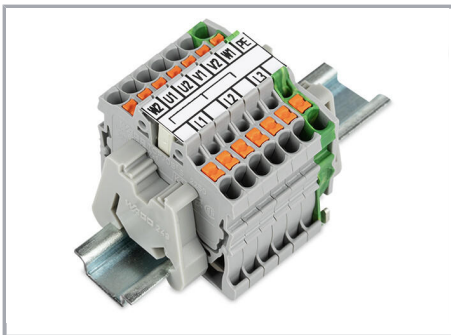

Marking strip (2009-110) inserted in the marking slot with jumper symbols of the inserted jumper (2000-405/011-000 Delta Jumper) (picture shows terminal blocks with push-buttons)

### Testing

Subject to changes. Please also observe the further product documentation!

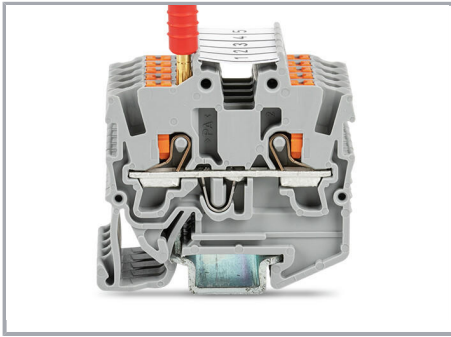


Testing with a 2 mm Ø 210-136 Test Plug (max. 42 V).

### Marking



Snapping a WMB marking strip into a marker slot.

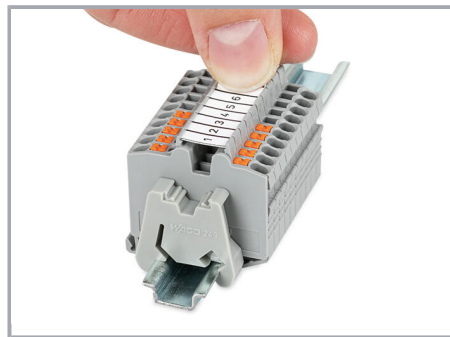

Snapping a marking strip (2009-110) into a marker slot.

### Product family

#### TOPJOB® S

TOPJOB® S: In various industrial applications and modern building installations, WAGO's wide and versatile range of rail-mount terminal blocks provides more than just reliable electrical connections.

[Show all products from the family](#)

Subject to changes. Please also observe the further product documentation!