

# CONSTANT CURRENT LED DRIVER

## 3-12VDC 3WATT

### POWERPAX: PLC3512-01

#### Features:

- Input Voltage 100-240vac
- IP20 Rated
- Low Profile
- Compact Plastic Low Profile enclosure
- 1 Year Warranty



#### Description:

The Range of 3watt Constant Current LED Drivers are housed in a compact light weight high quality IP20 plastic enclosure with covered input & output terminals suitable for general Indoor LED applications

Specification	
Part Number	PLC3512-01
Output Voltage Rating	3vdc to 12vdc
Output Current Range	350mA +/-6%
Rated Power	3 Watt
Dimensions	42 x 40 x 21mm
Input Voltage Range	100-240VAC
Input Voltage Frequency	50-60Hz
Inrush Current	20A
Efficiency	60%
Overload Protection	100-135% rated output power
Short Circuit Protection	Automatic Recovery
Working Temperature	-10°C~+40°C
Relative Humidity	20%~95%
MTBF	50k hours
Safety Standards	UL, Cul, class2 E301933,CLASS1 E252929,CE, EN61347 / EN55015

#### General Note


TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

# CONSTANT CURRENT LED DRIVER

## 3-12VDC 3WATT

POWERPAX: PLC3512-01

### Diagrams

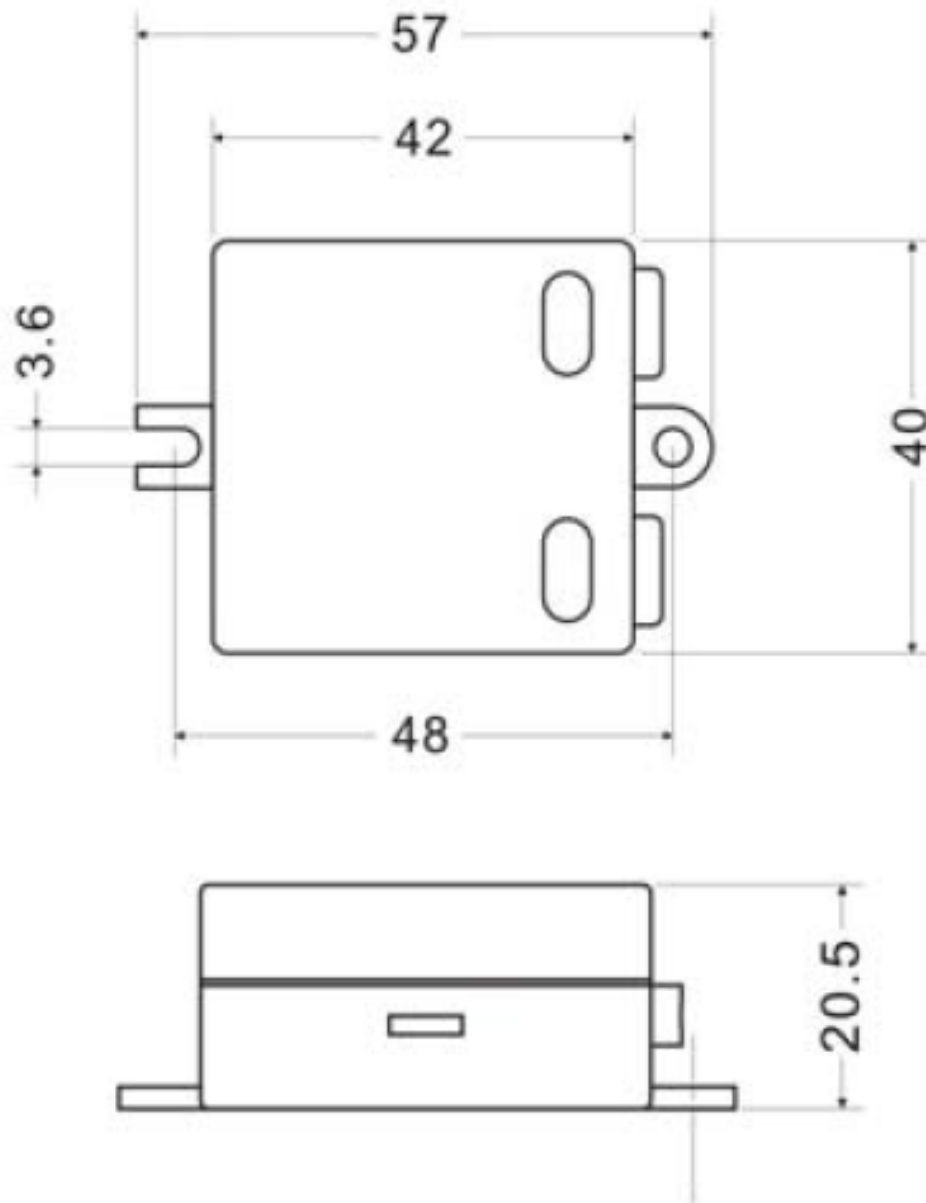

### POWERPAX

General Note  
TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

TT Electronics IoT Solutions Ltd  
Tofts Farm East, Brenda Road, Hartlepool, TS25 2BQ, UK  
t: +44 (0) 1429 852 500