


ZRA21MR60J476ME11#

“#” indicates a package specification code.



< List of part numbers with package codes >
ZRA21MR60J476ME11L

Appearance & Shape

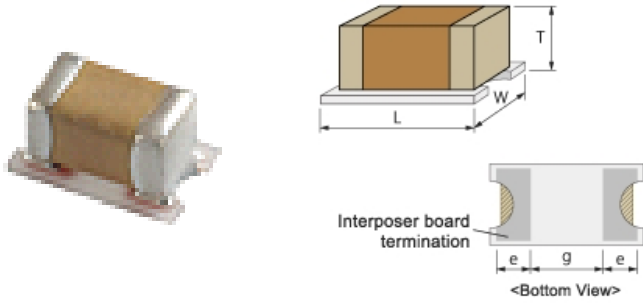

References

Packaging	Specifications	Standard Packing Quantity
L	180Embossed Tape	3000

Mass (typ.)	
1 piece	13.0mg
φ180mm Reel	109g

Notices

Derating1. Only for mobile devices

Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications. Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

ZRA21MR60J476ME11#

“#” indicates a package specification code.

Specifications

Length	2.4±0.1mm
Width	1.65±0.1mm
Thickness	1.15+0.05/-0.15mm
Capacitance	47μF ±20%
Distance between external terminals g	0.8±0.1mm
External terminal size e	0.7±0.1mm
Operating Temperature Range	-55°C to 85°C
Rated Voltage	6.3Vdc
Capacitance change rate	±15.0%
Temperature characteristics (complied standard)	X5R(EIA)
Temperature range of temperature characteristics	-55°C to 85°C

Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.