

## ATF5.5X100 | ATF - PROTWIST® screwdrivers for slotted head screws - forged blades




### Standards:

NF ISO 2380-1, NF ISO 2380-2, ISO 2380-1, ISO 2380-2, DIN ISO 2380-1, DIN ISO 2380-2, ASME B107.600

### Description:

- Forged blade with excellent tip fibre for high torsion strength.
- Extra-long shank up to 250 mm for difficult and remote access.
- Inline Hardening Process – +100% Tip Life and +100% Bar Strength.
- Handle Material - Softer for more Comfort and still Chemical Resistant.
- Blade " tri-coating " treatment (Zinc-Nickel-Chromium) - 4x Corrosion Resistance.
- Handle 'Channel' - +10% Torque.
- Laser Marking - gives virtually Permanent Marking.
- CNC tip machining - gives better Screw Fit increasing Torque Transfer and Reducing Wear.

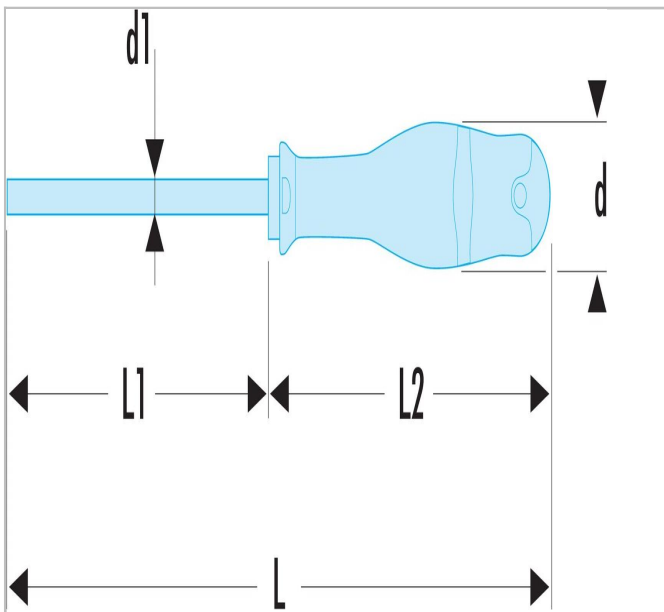

	<b>ATF5.5X100</b>
A [mm]	5.5
Diameter [mm]	30.0
Diameter D1 [mm]	5.5
Length L1 [mm]	100.0
Length L [mm]	209.0
Length L2 [mm]	109.0
Thickness E [mm]	1.0
Width [mm]	5.5
Weight [g]	76.0