

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0150160325**
Status: **Active**
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.50mm Pitch Premo-Flex One-Touch FFC Jumper with Ears, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 30 Circuits

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification 150160001-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Cable
 Series 15016
 Crimp Quality Equipment Yes
 Overview FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Product Name Premo-Flex FFC Jumper
 UPC 195842134799

Physical

Cable Length 152.00mm
 Circuits (Loaded) 30
 Contact Layout Type A (same side)
 Material - Plating Mating Gold
 Packaging Type Bag
 Pitch - Mating Interface 0.50mm
 Temperature Range - Operating -40° to +105°C
 Wire Size AWG N/A
 Wire/Cable Type Flat Flex Cable


Electrical

Current - Maximum per Contact 0.3A
 Voltage - Maximum N/A

Material Info

Reference - Drawing Numbers

Product Specification 150160001-000
 Sales Drawing 150160001-001

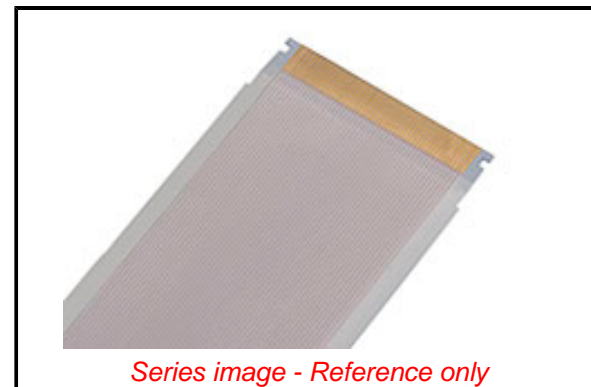

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2021)4569-DC (8
 July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

15016 Series

Mates With

Easy-On FFC/FPC One-Touch Connector
2004850430 , 2004850530