


KERN BIC3T-3L

High resolution floor scale with 2x3000 [d] and the best price to performance ratio

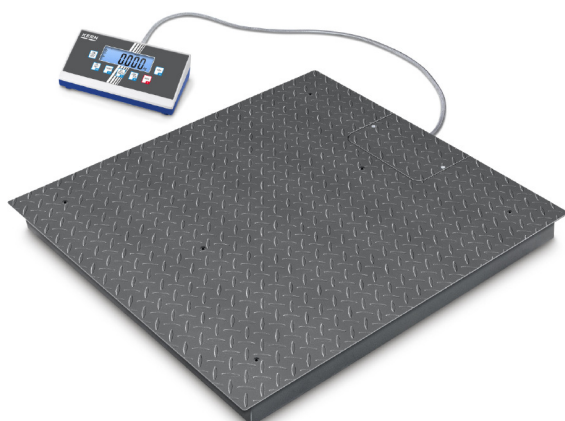

Measuring system

Adjustment options:	External calibration
Linearity:	1,500 kg 3 kg
Load cell connection:	4-wire
Number of weighing ranges:	2
Readability [d]:	500 g 1000 g
Recommended adjusting weight:	3000 kg (M1)
Repeatability:	500 g 1000 g
Resolution:	3 3.000
Stabilisation time under laboratory conditions:	2 s
Tare range:	-3 t
Warm up time:	10 min 10 min
Weighing capacity [Max]:	1,500 t 3 t
Weighing system:	Strain gauge
Weighing units:	lb kg PCS

Display

Display digit height (large):	2,500 cm
-------------------------------	----------

Functions

Data hold function:	yes
---------------------	-----

Environmental conditions

Maximum humidity:	80 %
Maximum operating temperature:	40 °C
Minimum ambient temperature:	-10 °C
Minimum humidity:	0 %

Power supply

Battery:	4x1.5 V AA
Input voltage:	100 V - 240V AC 50/60Hz 0.3A
Mains adapter:	Mains adapter external
Mains adapter/adaptor included:	EURO AUS UK US
Operating time:	60 h

Services (optional)

Adjustment at the location of installation: 961-252

DAkkS Certificate:	963-132
--------------------	---------

Category

Brand:	KERN
Category:	Balances
Product Group:	Floor scale

Packaging & shipping

Delivery:	48 h
Dimensions packaging (WxDxH):	1550 x 1550 x 265 mm
Gross weight:	180 kg
Net weight:	155 kg
Shipping method:	Freight forwarder

Construction

Cable length:	5 m
Cable length of display device:	5 m
Dimensions (WxDxH):	1500 x 1500 x 108 mm
Dimensions of display device (WxDxH):	235 x 114 x 51 mm
Dimensions of weighing plate (WxDxH):	1500 x 1500 x 108 mm
Level indicator:	yes
Revolving screw feet:	yes
Weighing surface (WxD):	1500 x 1500 mm

Piktogramme

STANDARD



OPTION

