


# KERN EOC300K-3

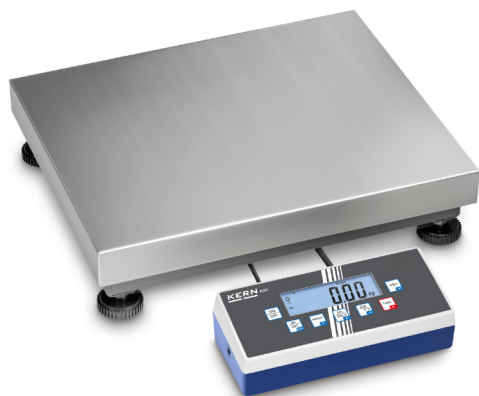

Robust and high-resolution platform scale with practical Flip/Flop display device for greatest ease of use



## Measuring system

Adjustment options:	External calibration
Linearisation (points):	3
Linearity:	15 g   30 g
Load cell connection:	4-wire
Readability [d]:	5 g   10 g
Recommended adjusting weight:	300 kg (F2)
Repeatability:	5 g   10 g
Resolution:	30 30.000
Stabilisation time under laboratory conditions:	2 s
Tare range:	300 kg
Warm up time:	2 h
Weighing capacity [Max]:	150 kg   300 kg
Weighing system:	Strain gauge
Weighing units:	g lb oz kg PCS

## Display

Display digit height (large):	2,500 cm
Display digit height (small):	2,500 cm

## Counting

Counting resolution:	30000
Minimum piece weight at piece counting (Laboratory):	10 g
Minimum piece weight at piece counting (Normal):	100 g

## Functions

Counting function:	yes
Percentage determination:	yes
Vibration-free weighing (Animal weighing program):	yes
Weighing with tolerance range:	yes

## Environmental conditions

Maximum humidity:	80 %
Maximum operating temperature:	40 °C
Minimum ambient temperature:	-10 °C
Minimum humidity:	0 %

## Power supply

Charging time:	3 h
Input voltage:	100V-240V 0.4A
Mains adapter:	Mains adapter external
Mains adapter/adapter included:	EURO CH UK
Operating time:	100 h
Operating time (Backlight off):	43 h
Operating time (Backlight on):	26 h
Rechargeable battery:	Rchrg. battery optional - intern

## Services (optional)

Adjustment at the location of installation: 961-249

DAkkS Certificate:	963-129
--------------------	---------

## Category

Brand:	KERN
Category:	Balances
Product Group:	Industrial scale

## Packaging & shipping

Delivery:	24 h
Dimensions packaging (WxDxH):	870 x 490 x 150 mm
Gross weight:	12,500 kg
Net weight:	9 kg
Shipping method:	Parcel service

## Construction

Cable length of display device:	3 m
Dimensions of display device (WxDxH):	268 x 115 x 80 mm
Dimensions of weighing plate (WxDxH):	500 x 400 x 120 mm
of stand:	33 cm
Level indicator:	yes
Material weighing plate:	stainless steel
Revolving screw feet:	yes
Wall mount:	yes

# KERN EOC300K-3



Robust and high-resolution platform scale with practical Flip/Flop display device for greatest ease of use

## Piktogramme

### STANDARD



### OPTION

