

# KERN IFS100K-3L



Industrial counting scale with convenient decimal keypad for easy data entry, counting resolution up to 75000 points - also with EC type approval [M]



## Measuring system

Adjustment options:	External calibration
Linearity:	6 g   10 g
Load cell connection:	6-wire
Readability [d]:	1 g   2 g
Recommended adjusting weight:	150 kg (F2)
Repeatability:	1 g   2 g
Resolution:	75 75.000
Stabilisation time under laboratory conditions:	2 s
Tare range:	-150 kg
Warm up time:	2 h   2 h
Weighing capacity [Max]:	75 kg   150 kg
Weighing system:	Strain gauge
Weighing units:	kg

## Display

Display digit height (large):	1,650 cm
Display digit height (small):	1,350 cm

## Counting

Counting resolution:	60000
Minimum piece weight at piece counting (Laboratory):	2,500 g
Minimum piece weight at piece counting (Normal):	25 g

## Functions

Counting function:	yes
Function to save totals:	yes
Peak function:	yes
Percentage determination:	yes
PRE-TARE function:	yes
Weighing with tolerance range:	yes

## Environmental conditions

Maximum humidity:	80 %
Maximum operating temperature:	40 °C
Minimum ambient temperature:	0 °C
Minimum humidity:	0 %

## Power supply

Charging time:	12 h
Input voltage:	100-240V50/60Hz 190mA
Mains adapter:	Mains adapter external
Mains adapter/adaptor included:	EURO CH UK US
Operating time (Backlight off):	18 h
Operating time (Backlight on):	8 h
Rechargeable battery:	Rchrg. battery optional (factory)

## Services (optional)

DAkkS Certificate:	963-129
--------------------	---------

## Category

Brand:	KERN
Category:	Balances
Product Group:	Industrial scale

## Packaging & shipping

Delivery:	24 h
Dimensions packaging (WxDxH):	1045 x 660 x 240 mm
Gross weight:	24,500 kg
Net weight:	19,900 kg
Shipping method:	Parcel service

## Construction

Cable length of display device:	3 m
Dimensions of display device (WxDxH):	260 x 150 x 65 mm
Dimensions of weighing plate (WxDxH):	650 x 500 x 140 mm
of stand:	60 cm
Level indicator:	yes
Material weighing plate:	stainless steel
Overall dimensions mounted (WxDxH):	650 x 500 x 745 mm
Revolving screw feet:	yes
Wall mount:	yes
Weighing surface (WxD):	650 x 500 mm


# KERN IFS100K-3L



Industrial counting scale with convenient decimal keypad for easy data entry, counting resolution up to 75000 points - also with EC type approval [M]

## Piktogramme

### STANDARD

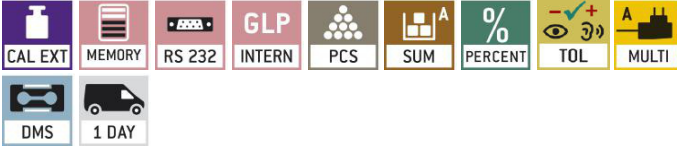

### OPTION



### FACTORY

