


NEMA TYPE 4 ENVIROLINE® SERIES SINGLE DOOR ENCLOSURES



SCE-12EL1206LP
shown smaller
than actual size.



- 0.075" Carbon Steel
- Seams Continuously Welded and Ground Smooth
- Flange Trough Collar Around All Sides of Door Opening
- Oil-Resistant Gasket
- Collar Studs Provided for Mounting Optional Panels
- Concealed Hinge
- Removable and Interchangeable Doors
- Black Quarter Turn Latches
- Latches Are Opened or Closed with a Screwdriver
- Mounting Holes in Back of Enclosure
- Mounting Hardware, Sealing Washer and Hole Plug Included
- Removable Print Pocket
- Ground Studs on Door and Body
- Optional Tamper-Resistant Inserts Are Available
- Optional Mounting Feet Available
- Door Hardware Available

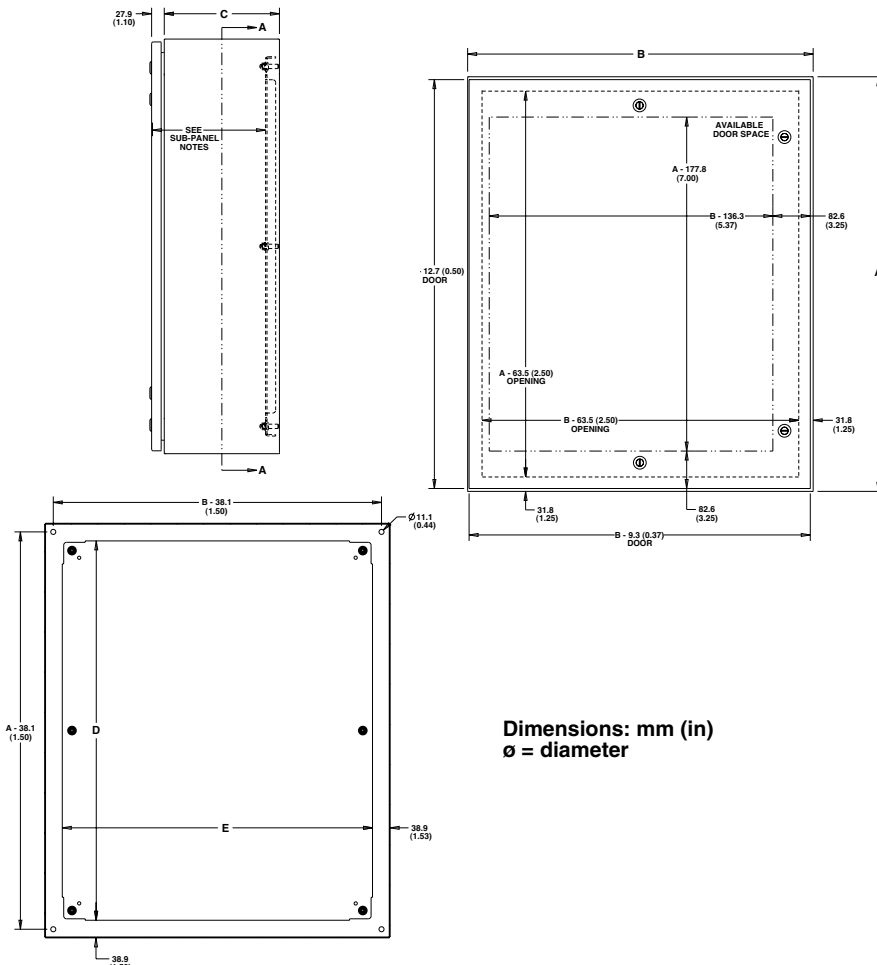

Dimensions: mm (in)
 ø = diameter

Application

Designed to house electrical and electronic controls, instruments and components. Provides protection from dust, oil and water. For outdoor application a drip shield is recommended.

Finish

ANSI-61 gray powder coating inside and over phosphatized surfaces. Optional panels are powder coated white.

Industry Standards

- NEMA Type 4, 12, & 13
- UL Listed Type 4 & 12
- CSA Type 4 & 12
- IEC 60529 IP 66

SUB-PANEL NOTES:
 Dimensions are from the inside of the door
 C + 8.1 (0.32) for flat sub-panels
 C - 4.5 (0.18) for bent sub-panels

LATCH NOTES:
 Enclosures < 609.6 (24.00") in height require only one latch centered on door.
 Enclosures >= 609.6 (24.00") and < 1016 (40.00") in height require two latches on door.
 Enclosures >= 1016 (40.00") require three latches on door.
 Omit center latch top and bottom of door when door width is <= 762 (30.00")

To Order

TYPE 4 ENVIROLINE® SERIES SINGLE DOOR ENCLOSURES

MODEL NO.	ENCLOSURES (inch)			SUB-PANEL (inch)		
	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-12EL1206LP	12.00	12.00	6.00	SCE-12DLP12	9.00	9.00
SCE-12EL2406LP	12.00	24.00	6.00	SCE-12P24	9.00	21.00
SCE-16EL1206LP	16.00	12.00	6.00	SCE-16P12	13.00	9.00
SCE-16EL1208LP	16.00	12.00	8.00	SCE-16P12	13.00	9.00
SCE-16EL1408LP	16.00	14.00	8.00	SCE-16DLP14	13.00	11.00
SCE-16EL1606LP	16.00	16.00	6.00	SCE-16P16	13.00	13.00
SCE-16EL1608LP	16.00	16.00	8.00	SCE-16P16	13.00	13.00
SCE-16EL2006LP	16.00	20.00	6.00	SCE-20P16	17.00	13.00
SCE-16EL2008LP	16.00	20.00	8.00	SCE-20P16	17.00	13.00
SCE-20EL1206LP	20.00	12.00	6.00	SCE-20P12	17.00	9.00
SCE-20EL1606LP	20.00	16.00	6.00	SCE-20P16	17.00	13.00
SCE-20EL1608LP	20.00	16.00	8.00	SCE-20P16	17.00	13.00
SCE-20EL1612LP	20.00	16.00	12.00	SCE-20P16	17.00	13.00
SCE-20EL2006LP	20.00	20.00	6.00	SCE-20P20	17.00	17.00
SCE-20EL2008LP	20.00	20.00	8.00	SCE-20P20	17.00	17.00
SCE-20EL2012LP	20.00	20.00	12.00	SCE-20P20	17.00	17.00
SCE-20EL2408LP	20.00	24.00	8.00	SCE-24P20	21.00	17.00
SCE-24EL1206LP	24.00	12.00	6.00	SCE-12P24	9.00	21.00
SCE-24EL1606LP	24.00	16.00	6.00	SCE-24P16	21.00	13.00
SCE-24EL1608LP	24.00	16.00	8.00	SCE-24P16	21.00	13.00
SCE-24EL2006LP	24.00	20.00	6.00	SCE-24P20	21.00	17.00

To Order

TYPE 4 ENVIROLINE® SERIES SINGLE DOOR ENCLOSURES (CONTINUED)

MODEL NO.	ENCLOSURES (inch)			MODEL NO.	SUB-PANEL (inch)	
	HEIGHT (A)	WIDTH (B)	DEPTH (C)		HEIGHT (D)	WIDTH (E)
SCE-24EL2008LP	24.00	20.00	8.00	SCE-24P20	21.00	17.00
SCE-24EL2010LP	24.00	20.00	10.00	SCE-24P20	21.00	17.00
SCE-24EL2012LP	24.00	20.00	12.00	SCE-24P20	21.00	17.00
SCE-24EL2016LP	24.00	20.00	16.00	SCE-24P20	21.00	17.00
SCE-24EL2406LP	24.00	24.00	6.00	SCE-24P24	21.00	21.00
SCE-24EL2408LP	24.00	24.00	8.00	SCE-24P24	21.00	21.00
SCE-24EL2410LP	24.00	24.00	10.00	SCE-24P24	21.00	21.00
SCE-24EL2412LP	24.00	24.00	12.00	SCE-24P24	21.00	21.00
SCE-24EL2416LP	24.00	24.00	16.00	SCE-24P24	21.00	21.00
SCE-24EL3008LP	24.00	30.00	8.00	SCE-30P24	27.00	21.00
SCE-24EL3010LP	24.00	30.00	10.00	SCE-30P24	27.00	21.00
SCE-30EL1606LP	30.00	16.00	6.00	SCE-30P16	27.00	13.00
SCE-30EL2008LP	30.00	20.00	8.00	SCE-30P20	27.00	17.00
SCE-30EL2010LP	30.00	20.00	10.00	SCE-30P20	27.00	17.00
SCE-30EL2408LP	30.00	24.00	8.00	SCE-30P24	27.00	21.00
SCE-30EL2410LP	30.00	24.00	10.00	SCE-30P24	27.00	21.00
SCE-30EL2412LP	30.00	24.00	12.00	SCE-30P24	27.00	21.00
SCE-30EL2416LP	30.00	24.00	16.00	SCE-30P24	27.00	21.00
SCE-30EL2420LP	30.00	24.00	20.00	SCE-30P24	27.00	21.00
SCE-30EL2424LP	30.00	24.00	24.00	SCE-30P24	27.00	21.00
SCE-30EL3008LP	30.00	30.00	8.00	SCE-30P30	27.00	27.00
SCE-30EL3010LP	30.00	30.00	10.00	SCE-30P30	27.00	27.00
SCE-30EL3012LP	30.00	30.00	12.00	SCE-30P30	27.00	27.00
SCE-30EL3608LP	30.00	36.00	8.00	SCE-36P30	33.00	27.00
SCE-36EL2408LP	36.00	24.00	8.00	SCE-36P24	33.00	21.00
SCE-36EL2410LP	36.00	24.00	10.00	SCE-36P24	33.00	21.00
SCE-36EL2412LP	36.00	24.00	12.00	SCE-36P24	33.00	21.00
SCE-36EL2416LP	36.00	24.00	16.00	SCE-36P24	33.00	21.00
SCE-36EL3008LP	36.00	30.00	8.00	SCE-36P30	33.00	27.00
SCE-36EL3010LP	36.00	30.00	10.00	SCE-36P30	33.00	27.00
SCE-36EL3012LP	36.00	30.00	12.00	SCE-36P30	33.00	27.00
SCE-36EL3016LP	36.00	30.00	16.00	SCE-36P30	33.00	27.00
SCE-36EL3020LP	36.00	30.00	20.00	SCE-36P30	33.00	27.00
SCE-36EL3608LP	36.00	36.00	8.00	SCE-36P36	33.00	33.00
SCE-36EL3612LP	36.00	36.00	12.00	SCE-36P36	33.00	33.00
SCE-36EL3616LP	36.00	36.00	16.00	SCE-36P36	33.00	33.00
SCE-40EL2412LP	40.00	24.00	12.00	SCE-40P24	37.00	21.00
SCE-42EL2410LP	42.00	24.00	10.00	SCE-42P24	39.00	21.00
SCE-42EL3008LP	42.00	30.00	8.00	SCE-42P30	39.00	27.00
SCE-42EL3010LP	42.00	30.00	10.00	SCE-42P30	39.00	27.00
SCE-42EL3012LP	42.00	30.00	12.00	SCE-42P30	39.00	27.00
SCE-42EL3016LP	42.00	30.00	16.00	SCE-42P30	39.00	27.00
SCE-42EL3608LP	42.00	36.00	8.00	SCE-42P36	39.00	33.00
SCE-42EL3610LP	42.00	36.00	10.00	SCE-42P36	39.00	33.00
SCE-42EL3612LP	42.00	36.00	12.00	SCE-42P36	39.00	33.00
SCE-42EL3616LP	42.00	36.00	16.00	SCE-42P36	39.00	33.00



SCE-12EL1206LP
shown smaller
than actual size.

To Order

TYPE 4 ENVIROLINE® SERIES SINGLE DOOR ENCLOSURES (CONTINUED)

ENCLOSURES (inch)				SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-48EL2408LP	48.00	24.00	8.00	SCE-48P24	45.00	21.00
SCE-48EL2412LP	48.00	24.00	12.00	SCE-48P24	45.00	21.00
SCE-48EL3010LP	48.00	30.00	10.00	SCE-48P30	45.00	27.00
SCE-48EL3016LP	48.00	30.00	16.00	SCE-48P30	45.00	27.00
SCE-48EL3608LP	48.00	36.00	8.00	SCE-48P36	45.00	33.00
SCE-48EL3610LP	48.00	36.00	10.00	SCE-48P36	45.00	33.00
SCE-48EL3612LP	48.00	36.00	12.00	SCE-48P36	45.00	33.00
SCE-48EL3616LP	48.00	36.00	16.00	SCE-48P36	45.00	33.00
SCE-48EL3620LP	48.00	36.00	20.00	SCE-48P36	45.00	33.00
SCE-60EL2412LP	60.00	24.00	12.00	SCE-60P24	57.00	21.00
SCE-60EL3610LP	60.00	36.00	10.00	SCE-60P36	57.00	33.00
SCE-60EL3612LP	60.00	36.00	12.00	SCE-60P36	57.00	33.00
SCE-60EL3616LP	60.00	36.00	16.00	SCE-60P36	57.00	33.00
SCE-60EL3620LP	60.00	36.00	20.00	SCE-60P36	57.00	33.00
SCE-72EL3012LP	72.00	30.00	12.00	SCE-72P30	69.00	27.00
SCE-72EL3016LP	72.00	30.00	16.00	SCE-72P30	69.00	27.00
SCE-72EL3024LP	72.00	30.00	24.00	SCE-72P30	69.00	27.00
SCE-72EL3612LP	72.00	36.00	12.00	SCE-72P36	69.00	33.00
SCE-72EL3616LP	72.00	36.00	16.00	SCE-72P36	69.00	33.00

Ordering Examples: SCE-12EL1206LP, NEMA Type 4 Enviroline® series single-door enclosure.

SCE-16EL2006LP, NEMA Type 4 Enviroline series single-door enclosure, 16 H x 20 W x 6" D, SCE-20P16, sub-panel.