

467BF.10 | 467BF - Metric hinged jointed combination wrenches





Standards:

NF ISO 1711-1, NF ISO 691, ISO 1711-1, ISO 691, DIN ISO 1711-1, DIN ISO 691

Description:

- Hinged head ratchet combination wrenches: to reach difficult access nuts.
- Compact ratchet mechanism and reversible by flipping the wrench.
- Increment 5° (6° for dimensions 8 and 9 mm).
- Ring head hinged at 180°.
- Open end head angled at 15°.
- Metric sizes: 8 to 19 mm.
- Presentation: satin chrome finish.

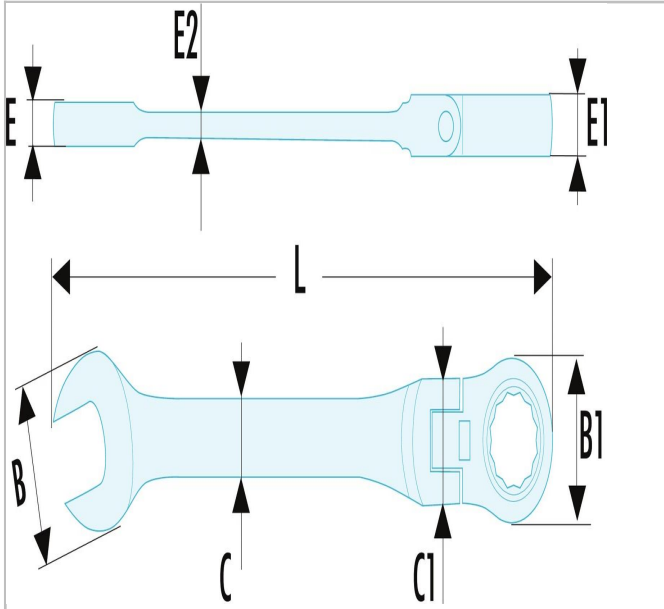

 FACOM	467BF.10
A [mm]	10.0
Length L [mm]	136.5
Thickness E [mm]	5.1
Thickness E1 [mm]	7.3
Thickness E2 [mm]	3.6
Head Height C [mm]	9.8
Head Width B [mm]	22.7
Head Width B1 [mm]	20.0
Weight [Kg]	0.053