


## Polyester Standard – 02.08 19 06

Plastic enclosure in glass fibre reinforced polyester consisting of lid, seal, incl. captive +/-stainless steel screws, base with 2 or 4 earthing screws

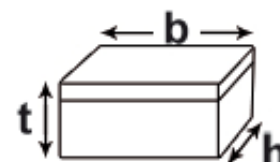

Dimensions H x W x D (mm)	75 x 190 x 56
Weight (g)	541
Order number	02.08 19 06
Product type	POS 02050

- + Robust plastic enclosure for automation technology and mechanical engineering
- + Fixing options for DIN rails and mounting plates
- + Universal configuration




### Technical Data

Material	glass fibre reinforced thermoset polyester
Colour	RAL 7000, squirrel grey, special colour on request
Ingress protection	IP 66 to EN 60529 (IP 67 on request)
Impact resistance	7 Joule in reference to EN 60079-0
Temperature range	CR (chloroprene) seal: -40°C to +100°C
Other versions on request	EMC, Silicone lid seal

## Polyester Standard – 02.08 19 06

### Number of cable glands

Maximum number of cable glands to DIN 50262\*

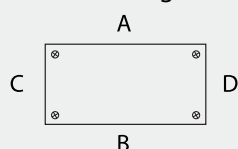

M	PG	Side	
		A/B	C/D
12	17,25	20	4
16	25,30	8	1
20	27,60	7	1
25	37,95	4	1
32	48,30		
40	60,95		
50	69,00		
63	74,75		
75			
85			

### Commercial Data

Country of origin	IN
Pieces per packaging	1
Customs tariff number	39269097
Weight (g)	541
GTIN	4250157900586

### ETIM Classification

ETIM-Class	EC000058
------------	----------

### Accessories

Description	Order number
External mounting brackets set = 4 pcs	10.03 11 01
Lead-sealing screw	12.01 90 01
Allen lid screws	12.01 80 05
DIN rails TS 15	10.06 10 10
Mounting plate	10.01 11 07