

Cat6 Patch Cables


24 AWG LSZH Cat6 UTP Patch Cables

Part No: 2993 - (Length) + (Colour) see chart

The range of LSZH Cat6 patch cables are manufactured using UL Approved Low Smoke Zero Halogen UTP stranded cable. Each assembly is fully moulded and fitted with high quality RJ45 connectors.

Features & Benefits

- Fully moulded, 4 twisted pair stranded 24 AWG assemblies available in eight lengths and seven colours
- Features UL rated, LSZH stranded UTP cable along with long-body 50 micron gold RJ connectors and moulded colour-matching boots
- Ideal for high speed Gigabit Ethernet systems with fault-free data/voice transmission
- Fully backward compatible with Cat.5/Cat.5E networks
- Contact our Sales Department for our cable labelling service available on short lead time, price quoted is per label, normally 2 labels required per cable one at each end

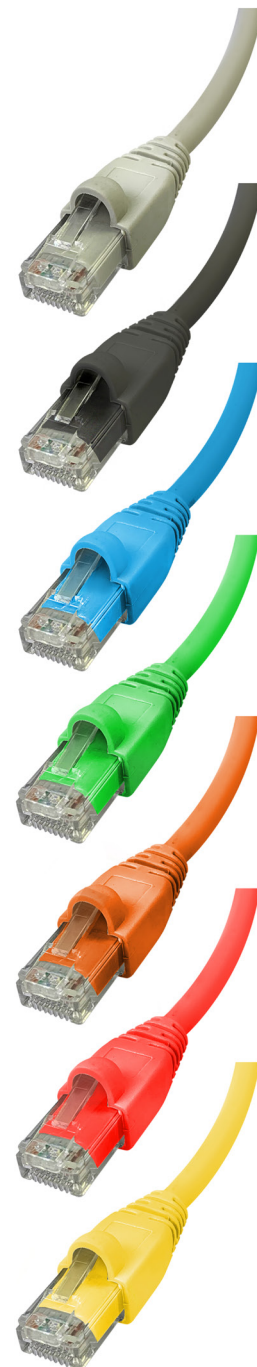



VIDEK

Cat6 Patch Cables

24 AWG LSZH Cat6 UTP Patch Cables

Part No: 2993 - (Length) + (Colour) see chart

Part Number Chart

Length	Beige 	Black 	Blue 	Green 	Orange 	Red 	Yellow 
0.5 Metre	2993-0.5	2993-0.5BK	2993-0.5B	2993-0.5G	2993-0.5RG	2993-0.5R	2993-0.5Y
1 Metre	2993-1	2993-1BK	2993-1B	2993-1G	2993-1RG	2993-1R	2993-1Y
1.5 Metre	2993-1.5	2993-1.5BK	2993-1.5B	2993-1.5G	2993-1.5RG	2993-1.5R	2993-1.5Y
2 Metre	2993-2	2993-2BK	2993-2B	2993-2G	2993-2RG	2993-2R	2993-2Y
3 Metre	2993-3	2993-3BK	2993-3B	2993-3G	2993-3RG	2993-3R	2993-3Y
5 Metre	2993-5	2993-5BK	2993-5B	2993-5G	2993-5RG	2993-5R	2993-5Y
8 Metre	2993-8	2993-8BK	2993-8B	2993-8G	2993-8RG	2993-8R	2993-8Y
10 Metre	2993-10	2993-10BK	2993-10B	2993-10G	2993-10RG	2993-10R	2993-10Y
15 Metre	2993-15	2993-15BK	2993-15B	2993-15G	2993-15RG	2993-15R	2993-15Y
20 Metre	2993-20	-	-	-	-	-	-
25 Metre	2993-25	-	2993-25B	2993-25G	-	2993-25R	2993-25Y
50 Metre	2993-50	-	-	-	-	-	-