

Update related to COVID-19. Learn More →



Products

Industries

About

Resources

Blog

Contact us

Find A Distributor

Home > Products > Cooling Fans > DC Axial Fans > 09238RA-12M-ET-D0

← Back To DC Axial Fans

Have a question about this product?




DC Axial Fans - 09238RA-12M-ET-D0



Get a sample

Resources

Specification Sheet	Series Data Sheet
Certificates	RoHS Certificate

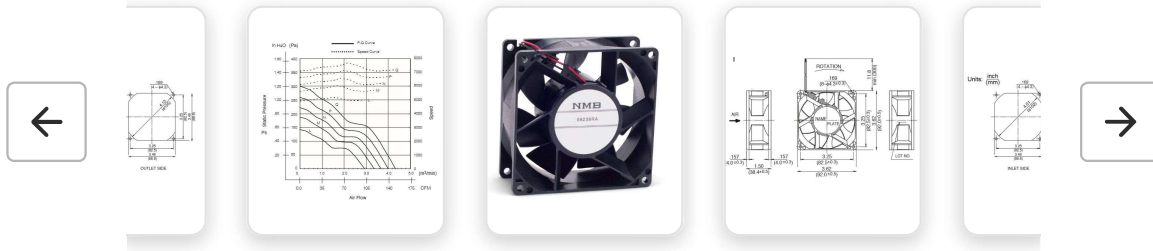

Specifications

Category	DC Axial Fans
Part Number	09238RA-12M-ET-D0
Frame Width [mm]	92
Frame Height [mm]	92
Frame Depth [mm]	38

Max. Air Flow [CFM]	118.65
Max. Air Flow [m3 per min]	3.36
Max. Static Pressure [In H2O]	0.75
Max. Static Pressure [Pa]	187
Fan Speed [RPM]	5700
Noise [dB]	56.5
Life Expectancy [L10]	100,000 hours at 25C
Bearing Type	Ball Bearing
Nominal Voltage [V]	12
Operating Voltage - Lower [V]	7
Operating Voltage - Upper [V]	13.8
Current [A]	1.15

Input Power [W]	13.8
Mass [g]	230
Tach / Locked Rotor Output	Tach Output
Status	Active

PRODUCTS

[See All Products](#) →

[Find A Distributor](#)

[Find a Sales Representative](#)

INDUSTRIES

[See All Industries](#)

[Automotive](#)

[Industrial](#)

[Medical](#)

[Consumer Technology](#)

[Smart City](#)

[Lighting Innovations](#)

RESOURCES

→ [See All Resources](#) →

[Application Notes & Whitepapers](#)

[Latest News](#)

[Videos](#)

CONTACT

NMB Technologies Corporation

[\(248\) 919-2250](#)

info@nmbtc.com

Have A Question?

Our precision component experts can help you find the right solutions.

[Contact Us Today](#)

[Find A Distributor](#)

[Find Sales Rep For Fans](#) →

