

Update related to COVID-19. Learn More →



Products

Industries

About

Resources

Blog

Contact us

Find A Distributor

Home > Products > Cooling Fans > DC Axial Fans > 11925SA-12Q-EL-D0

← Back To DC Axial Fans

Have a question about this product?




## DC Axial Fans - 11925SA-12Q-EL-D0



Get a sample

### Resources

Specification Sheet	Series Data Sheet
Certificates	RoHS Certificate

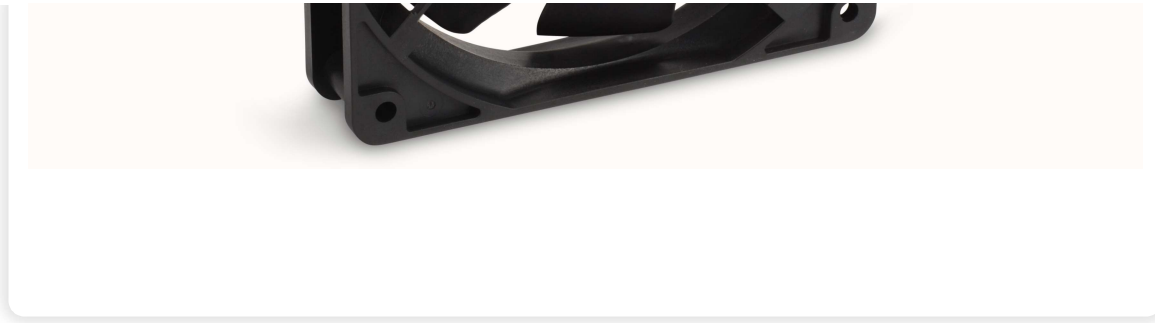

## Specifications

<b>Category</b>	DC Axial Fans
<b>Part Number</b>	11925SA-12Q-EL-D0
<b>Frame Width [mm]</b>	119
<b>Frame Height [mm]</b>	119
<b>Frame Depth [mm]</b>	25

<b>Max. Air Flow [CFM]</b>	113
<b>Max. Air Flow [m3 per min]</b>	3.2
<b>Max. Static Pressure [In H2O]</b>	0.29
<b>Max. Static Pressure [Pa]</b>	73
<b>Fan Speed [RPM]</b>	3100
<b>Noise [dB]</b>	44
<b>Life Expectancy [L10]</b>	40,000 hours at 60C
<b>Bearing Type</b>	Ball Bearing
<b>Nominal Voltage [V]</b>	12
<b>Operating Voltage - Lower [V]</b>	7
<b>Operating Voltage - Upper [V]</b>	13.8
<b>Current [A]</b>	0.47

<b>Input Power [W]</b>	5.64
<b>Mass [g]</b>	165
<b>Tach / Locked Rotor Output</b>	Locked Rotor
<b>Status</b>	Active

**PRODUCTS**[See All Products](#) →[Find A Distributor](#)[Find a Sales Representative](#)**INDUSTRIES**[See All Industries](#)[Automotive](#)[Industrial](#)[Medical](#)[Consumer Technology](#)[Smart City](#)[Lighting Innovations](#)**RESOURCES**[See All Resources](#) →[Application Notes & Whitepapers](#)[Latest News](#)[Videos](#)**CONTACT****NMB Technologies Corporation****(248) 919-2250****[info@nmbtc.com](mailto:info@nmbtc.com)**

## Have A Question?

**Our precision component experts can help you find the right solutions.**

[Contact Us Today](#)[Find A Distributor](#)[Find Sales Rep For Fans](#) →

