

The image displays several E-A-R Flex hearing protectors. There are two main types: one with a blue headband and yellow earplugs, and another with a yellow headband and red/orange earplugs. The blue protectors are shown in various configurations, including a full loop and a partial loop. The yellow protector is also shown in a loop configuration. The earplugs are yellow and have a textured, porous appearance. The headbands are made of a flexible material.

# **E·A·R** Flex™

Semi-Aural Hearing Protectors  
The Flexible Alternative

## FlexiCap™

SNR 23

FlexiCap offer the flexibility and compatibility of the new Flex band and the world's most popular semi-aural hearing protector. FlexiCap feature the innovative, patented hinged headband allowing for a variety of wearing positions without compromising other forms of personal protective equipment. The patented pod features the soft, smooth polyurethane cap design of our popular semi-aural E-A-RCaps.

### Features & Benefits Include:

- Hinged headband
- Easy Insertion
- Washable and replaceable pods
- Comfortable
- Excellent protection
- Replacement pods available
- Suitable for use with other PPE
- Tested to EN352-2

### Under The Chin

| Frequency (Hz)          | 63   | 125  | 250  | 500  | 1000 | 2000 | 4000 | 8000 |
|-------------------------|------|------|------|------|------|------|------|------|
| Mean Attenuation (dB)   | 26.1 | 22.8 | 20.1 | 18.6 | 22.0 | 32.7 | 36.5 | 37.0 |
| Standard Deviation (dB) | 5.2  | 6.0  | 5.0  | 3.3  | 3.4  | 4.1  | 4.3  | 8.3  |
| Assumed Protection (dB) | 20.8 | 16.8 | 15.1 | 15.3 | 18.6 | 28.6 | 32.2 | 28.7 |

H= 26; M= 19; L= 17;

## E-A-RCaps®

SNR 23

The world's most popular semi-aural. The E-A-RCaps is one of the lightest semi-aurals, providing day long comfort for workers exposed to noise.

### Features & Benefits Include:

- Easy to use
- Lightweight
- Comfortable
- Replacement pods available
- Tested to EN352-2


### Under The Chin

| Frequency (Hz)          | 63   | 125  | 250  | 500  | 1000 | 2000 | 4000 | 8000 |
|-------------------------|------|------|------|------|------|------|------|------|
| Mean Attenuation (dB)   | 21.0 | 20.2 | 19.8 | 19.1 | 23.2 | 33.4 | 41.0 | 40.7 |
| Standard Deviation (dB) | 4.1  | 4.4  | 4.2  | 4.3  | 3.7  | 4.5  | 2.9  | 5.4  |
| Assumed Protection (dB) | 16.9 | 15.8 | 15.5 | 14.8 | 19.5 | 29.0 | 38.1 | 35.2 |

H= 27; M= 19; L= 17;

# Semi-Aural Hearing Protector

## The Flexible

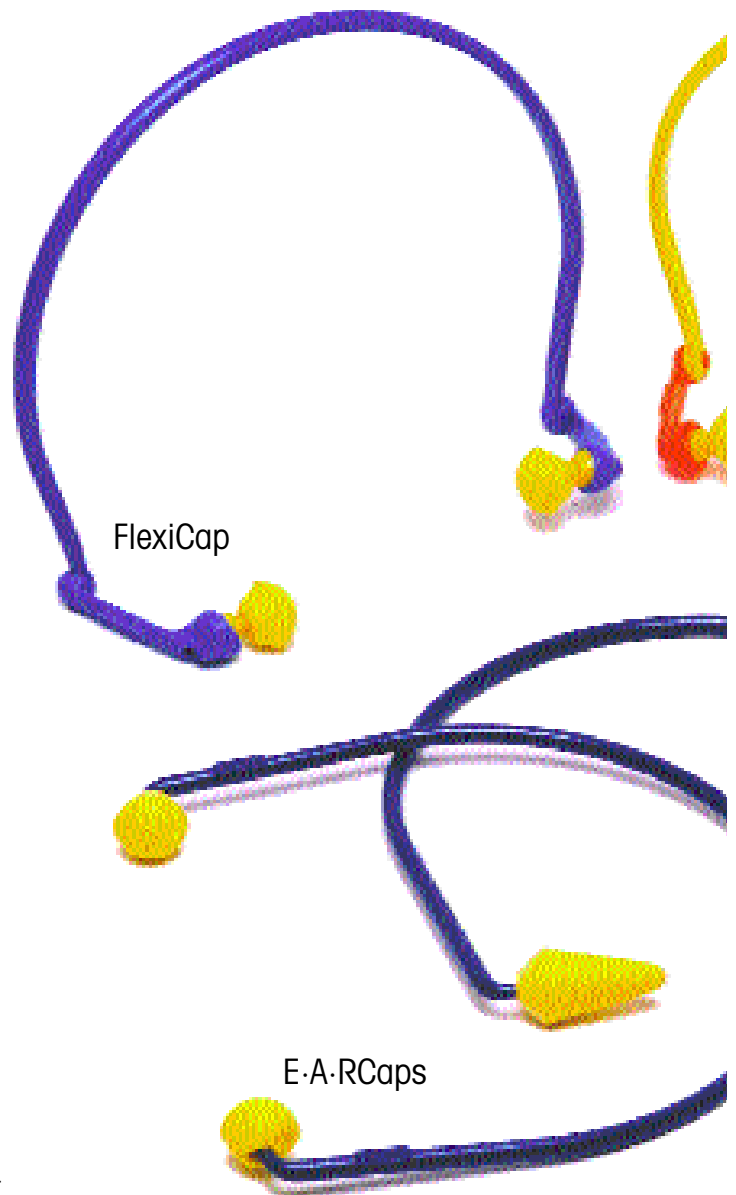

## CaboFlex®

SNR 21

This lightweight, semi-aural hearing protector is designed for use in noisy work areas. It can be carried comfortably around the neck. The curved insert swivels to align with the ear canal.

### Features & Benefits Include:

- Easy to use
- Lightweight
- Easily washed
- Durable
- Replacement pods available
- Tested to EN352-2

| Frequency          |
|--------------------|
| Mean Attenuation   |
| Standard Deviation |
| Assumed Protection |


# ing Protectors Alternative

**Hi-Viz™**

**SNR 23**

Flex Hi-Viz has a high visibility yellow headband with flexible orange tips which glow in poor light conditions. It is the ideal hearing protector to wear when you need to be seen and is recommended for use at airports or for utility workers. The soft foam pods effectively seal the ear canal entrance to make Flex Hi-Viz one of the easiest and most comfortable hearing protectors.

Viz

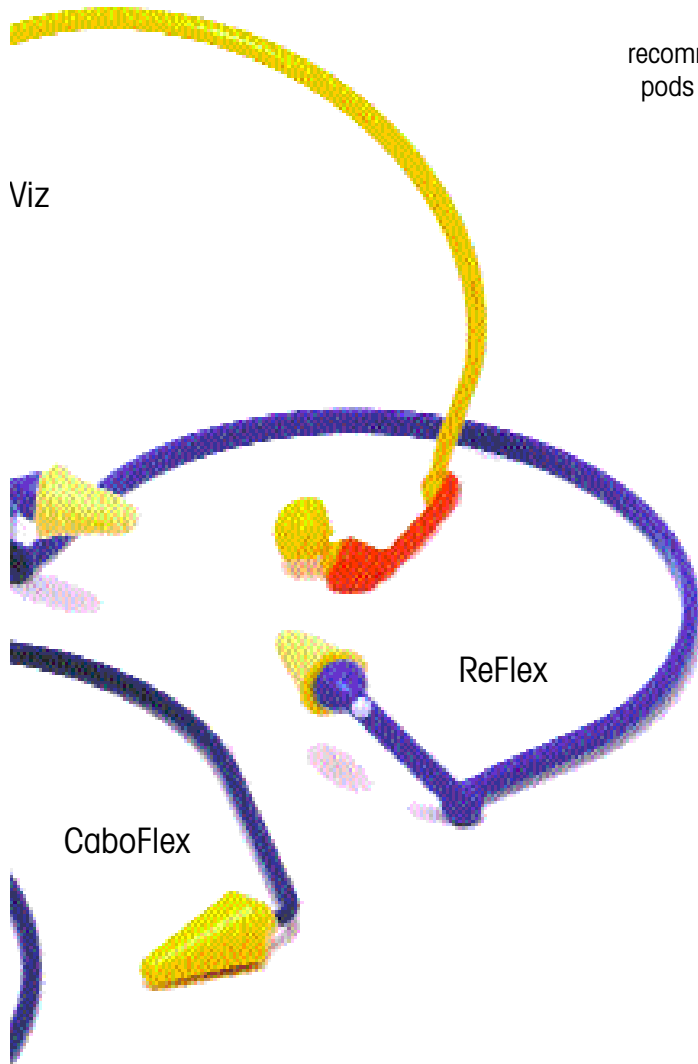

Features and Benefits Include:

- High visibility hinged headband
- Easy insertion
- Washable and replaceable pods
- Comfortable
- Excellent protection
- Replacement pods available
- Suitable for use with other PPE
- Tested to EN352-2

**Under The Chin**

| Frequency (Hz)          | 63   | 125  | 250  | 500  | 1000 | 2000 | 4000 | 8000 |
|-------------------------|------|------|------|------|------|------|------|------|
| Mean Attenuation (dB)   | 26.1 | 22.8 | 20.1 | 18.6 | 22.0 | 32.7 | 36.5 | 37.0 |
| Standard Deviation (dB) | 5.2  | 6.0  | 5.0  | 3.3  | 3.4  | 4.1  | 4.3  | 8.3  |
| Assumed Protection (dB) | 20.8 | 16.8 | 15.1 | 15.3 | 18.6 | 28.6 | 32.2 | 28.7 |

H= 26; M= 19; L= 17;

**ReFlex™**

**SNR 27**

ReFlex is a versatile, lightweight and comfortable alternative for ear muff wearers. Not only do they provide equal or higher protection than many ear muffs, they also feature pivoting headbands for multi positional wear. The open design helps keep the wearer cool in hot environments. The innovative patented headband allows the user tremendous flexibility in position, permitting easier use with other equipment.

Features & Benefits Include:

- Hinged headband
- Tapered E-A-RForm™ foam pods
- Easy Insertion
- Washable and replaceable pods
- Comfortable
- Excellent protection
- Tested to EN352-2

deal for anyone moving in and out of high  
the neck when not in use. Each conical

**Under The Chin**

|                         | 63   | 125  | 250  | 500  | 1000 | 2000 | 4000 | 8000 |
|-------------------------|------|------|------|------|------|------|------|------|
| Mean Attenuation (dB)   | 22.7 | 20.7 | 22.4 | 22.7 | 23.8 | 32.3 | 42.2 | 36.2 |
| Standard Deviation (dB) | 8.7  | 7.8  | 8.7  | 9.2  | 7.0  | 5.7  | 4.6  | 8.2  |
| Assumed Protection (dB) | 13.9 | 12.9 | 13.7 | 13.5 | 16.8 | 26.6 | 37.6 | 28.0 |

H= 25; M= 17; L= 15;

**Under The Chin**


| Frequency (Hz)          | 63   | 125  | 250  | 500  | 1000 | 2000 | 4000 | 8000 |
|-------------------------|------|------|------|------|------|------|------|------|
| Mean Attenuation (dB)   | 27.2 | 26.2 | 25.6 | 27.1 | 28.4 | 34.8 | 40.6 | 41.6 |
| Standard Deviation (dB) | 6.3  | 6.1  | 5.6  | 6.3  | 5.9  | 3.9  | 4.9  | 7.0  |
| Assumed Protection (dB) | 20.9 | 20.1 | 20.0 | 20.8 | 22.5 | 30.8 | 35.7 | 34.6 |

H= 30; M= 23; L= 22;

## ORDERING INFORMATION

Packaging: 40 pairs per dispenser, 10 dispensers per case

| Product Code | Product   | No. in Dispenser |
|--------------|-----------|------------------|
| EC 01 000    | E-A-RCaps | 40               |
| CF 01 000    | CaboFlex  | 40               |
| RF 01 000    | ReFlex    | 40               |
| FX 01 000    | FlexiCap  | 40               |
| FX 01 004    | Hi-Viz    | 40               |

 approved to EN352-2



For further information, Tel: 01625 878320 or Fax: 01625 877348

Aearo Ltd, First Avenue, Poynton, Stockport, Cheshire SK12 1FJ

E-mail: [sales@aearo.co.uk](mailto:sales@aearo.co.uk)

LT-02-112-0004