

CREALITY




CR-10 Smart Carborundum Glass Platform 310×315×4mm

MFR: 4004090065

Product Information


Easy to Take Models;
High Flatness Platform;
Solid as Rock;
Warp Resistant

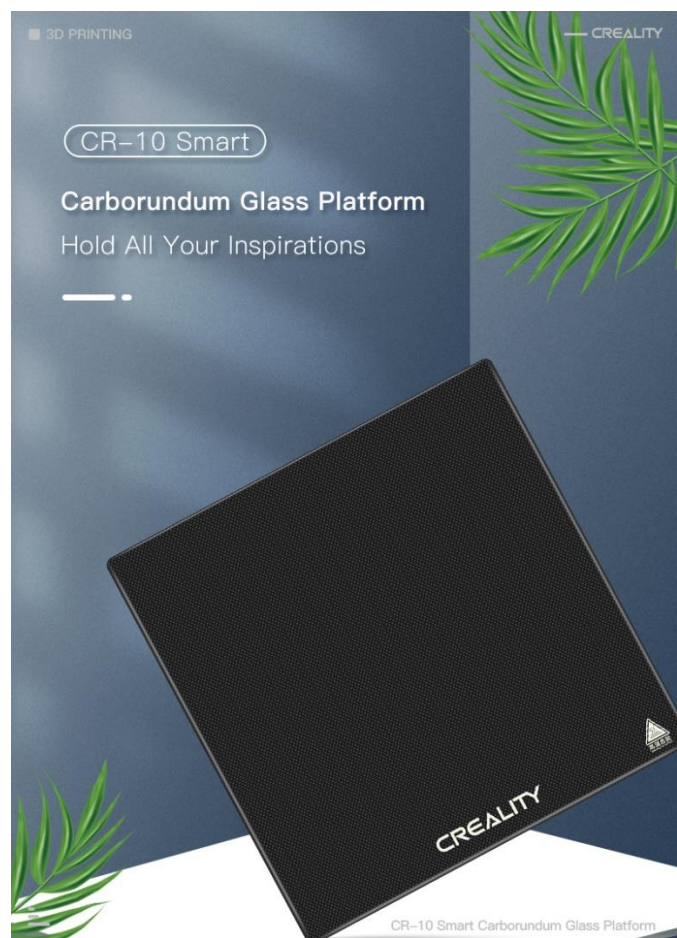

The beauty of dimensional balance

Outstanding simplicity gives 3D printing more imagination


Make every second of creation more expectant

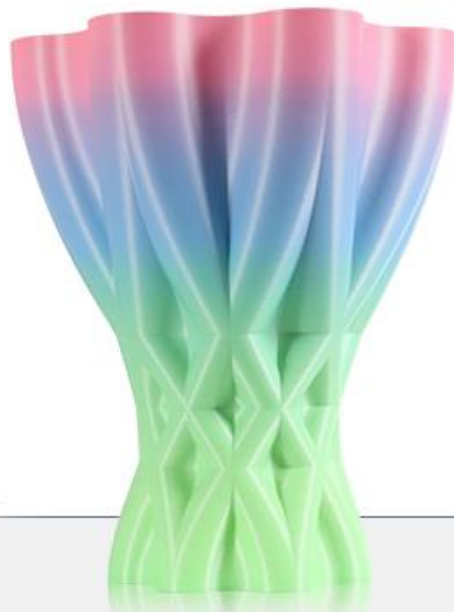



1 Second

Easy to Take Models

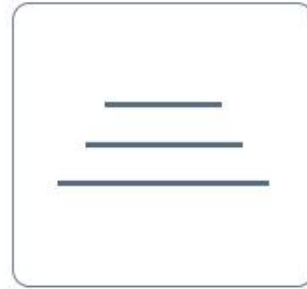

0.15mm

High Flatness Platform



8 Mohs Hardness

Solid as Rock



High Viscosity

Warp Resistent

It is necessary to choose
a good carborundum glass platform



Selected Materials



11 High-quality Processes




3 Quality Inspections

Take model in 1 second

You can easily take off model in one second with a scraper knife after hotbed cools down



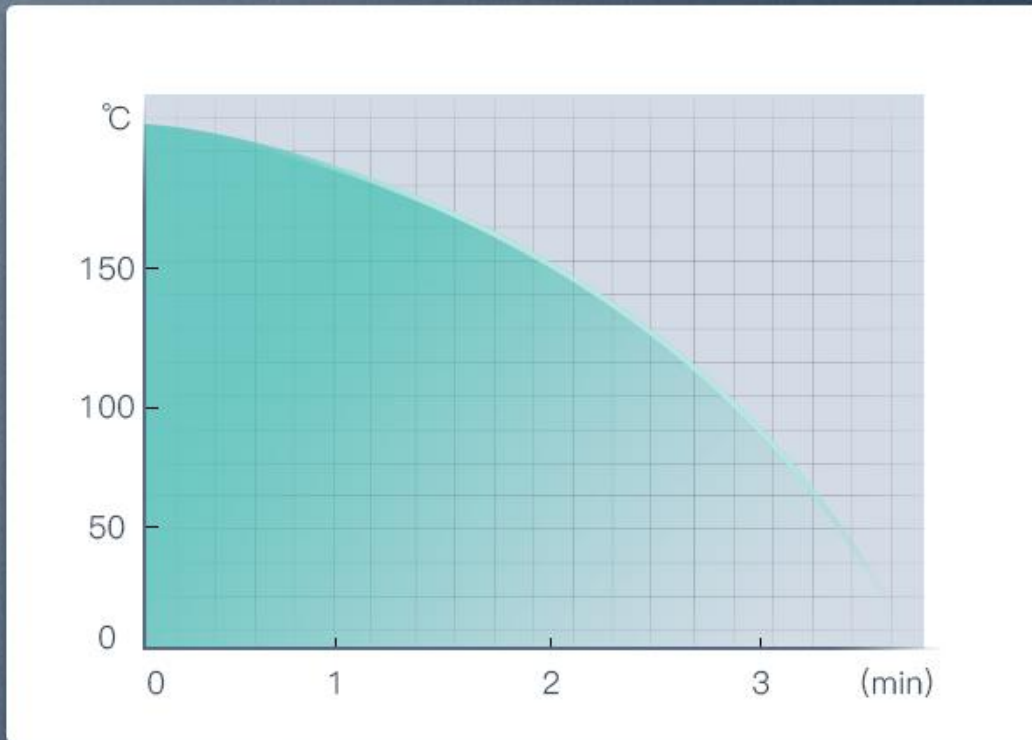


* It takes about 3 mins for hotbed cooling

Strong Adhesion, No Warping

Strong adhesion, no edge warping, exquisite surface,
no masking paper required, solid glue platform



Technical principle: composite nano-molecular coating will appear super viscosity after heating, so that model have strong adhesion

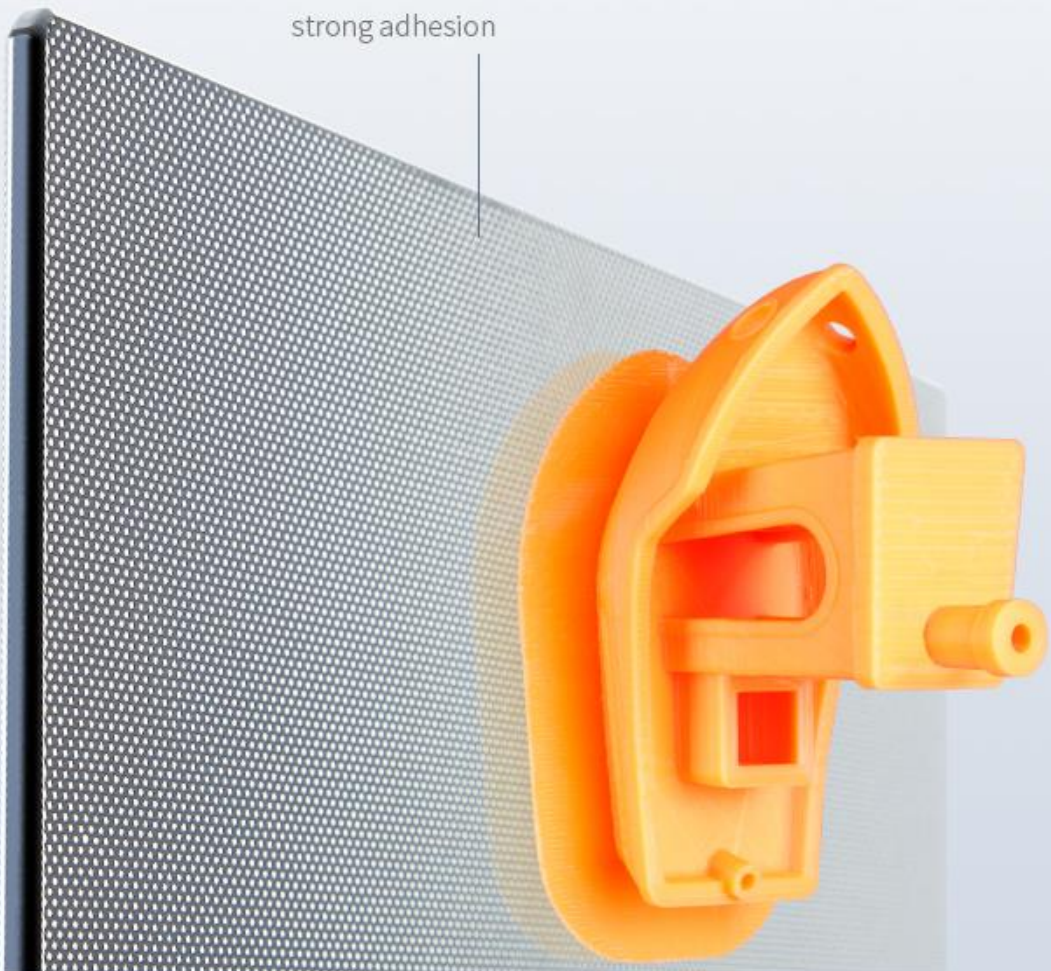

No Fear of High Temperature

Temperature can be up to 400°C high. It can work with all high temperature filaments



400°C



Flat Platform, More Stable Printing

0.15mm printing platform flatness prevents uneven adjustment of platform

Details at the bottom of the model are exquisitely presented



CREALITY

Good 3D Printing Platform
A stage for you to show your inspiration



Product Display



Product Parameters

Name

CR-10 Smart Carborundum Glass Platform

Applicable models

CR-10 Smart

Product size

310*315*4mm

Packing size

365*345*45mm

CREALITY

Products real shot

