
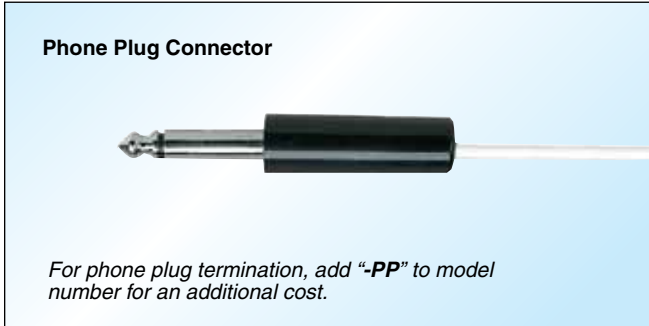


# Utility Handle Probe

THX-400-H Series

- ✓ Economical and Accurate Probe With Easy-Grip Molded Handle
- ✓ 300 mm (12") L Probe Can be Stored in Tool Boxes or Other Locations for Easy Access
- ✓ Retractable Cable Extends to 1.5 m (5') Standard Termination Has Stripped Leads
- ✓ Max Temperature 150°C (212°F) for Sensor, 135°C (275°F) for Handle
- ✓ 4.5 mm ( $\frac{3}{16}$ " ) Diameter, 300 Series Stainless Steel Sheath

THX-400-H-12 shown smaller than actual size.

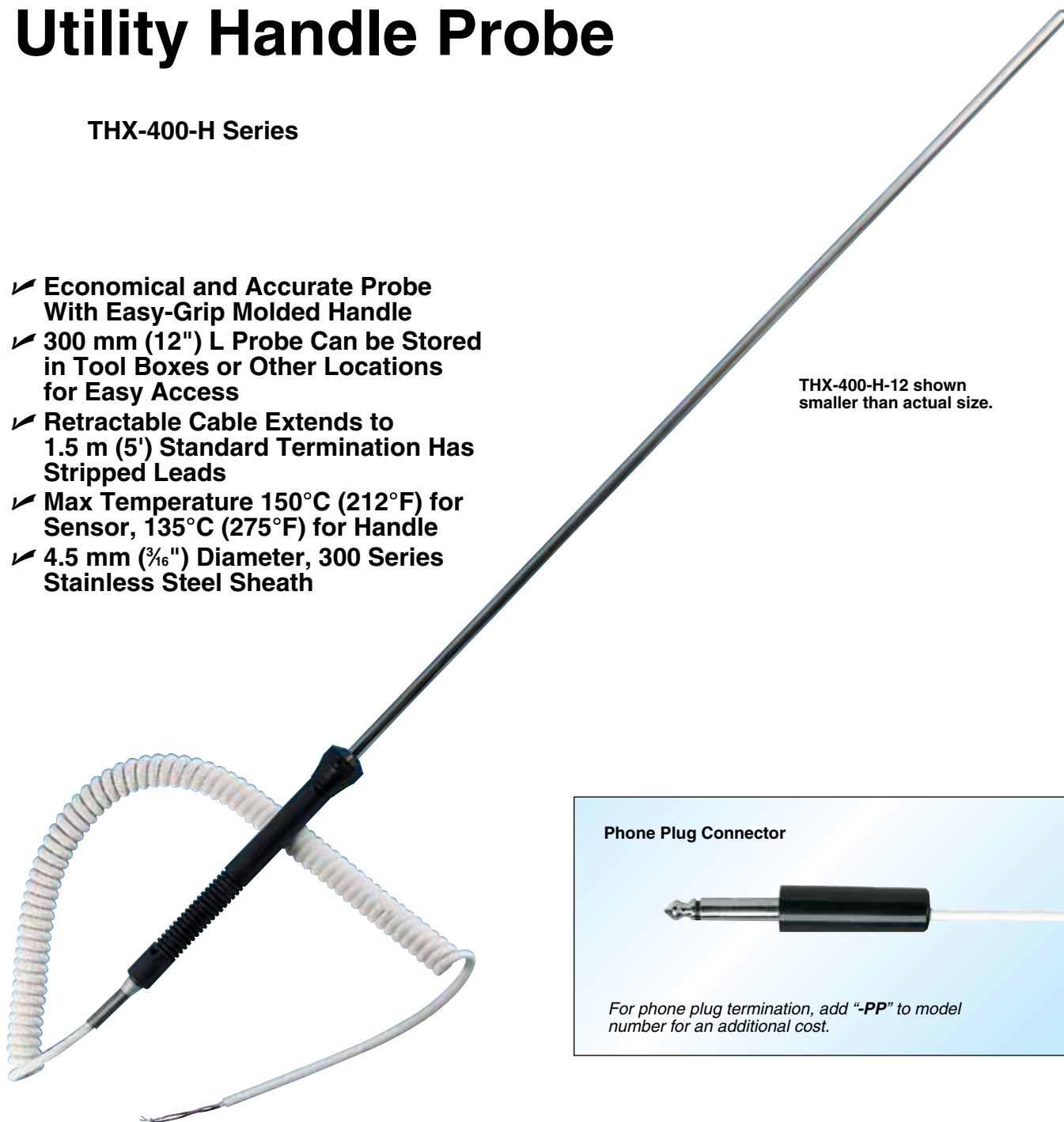

**To Order Visit [omega.com/thx-400-h](http://omega.com/thx-400-h) for Pricing and Details**

Model Number	Resistance @ 25°C	Interchangeability @ 0 to 70°C	Sheath Length	Sheath Diameter	Cable Termination
THX-400-H-12	2252 Ω	±0.2°C	300 mm (12")	4.5 mm ( $\frac{3}{16}$ " )	Stripped
THX-400-H-18	2252 Ω	±0.2°C	450 mm (18")	4.5 mm ( $\frac{3}{16}$ " )	Stripped
THX-400-H-24	2252 Ω	±0.2°C	600 mm (24")	4.5 mm ( $\frac{3}{16}$ " )	Stripped

**Notes:** For a phone plug, add "-PP" to the model number for an additional cost.  
**Ordering Examples:** THX-400-H-12, utility handle probe, 300 mm (12") long with retractable cable and stripped lead terminations.  
 THX-400-H-12-PP, utility handle probe, 300 mm (12") long with retractable cable and phone plug termination.

**Accessory**

Model Number	Description
CL26	High-precision handheld calibrator